



Polyamid Ausführung (Typ PB) s. S. 165.
Polyamide version (type PB) see page 165.

Clean Line Ausführung s. S. 225.
Clean Line version see page 225.

Aluminium Biegelgriffe AB

Werkstoff und Oberfläche:
Profilaluminium AlMgSi 0,5; besonders hochwertige Eloxal- ausführung, glaskugelgestrahlt, halbgläzend in 2 Standard- farben, sowie titanfarbig pulver- beschichtet, ähnlich RAL 9007.

Typ AB-R zum rückseitigen Anschrauben.

Typ AB-F für Schraubmontage von vorn; diese Ausführung erfolgt einschließlich Zylinder- schrauben mit Innensechskant DIN 912, Muttern DIN 934 und Unterlegscheiben DIN 125 aus Edelstahl.

Tragkraft:
min. 1.000 N.


Aluminium Bow Type Handles AB

Material and surface:
Profiled aluminium AlMgSi 0.5; high quality anodized, glass ball blasted with satin finish in 2 standard colours, also titanium coloured powder coated, similar to RAL 9007.

Typ AB-R screw attachment from behind.

Typ AB-F screw attachment from the front; this type supplied incl. cheese head screws with hexagon socket DIN 912, nuts DIN 934 and galvanized washers DIN 125 of stainless steel.

Stress resistance:
min. 1.000 N.

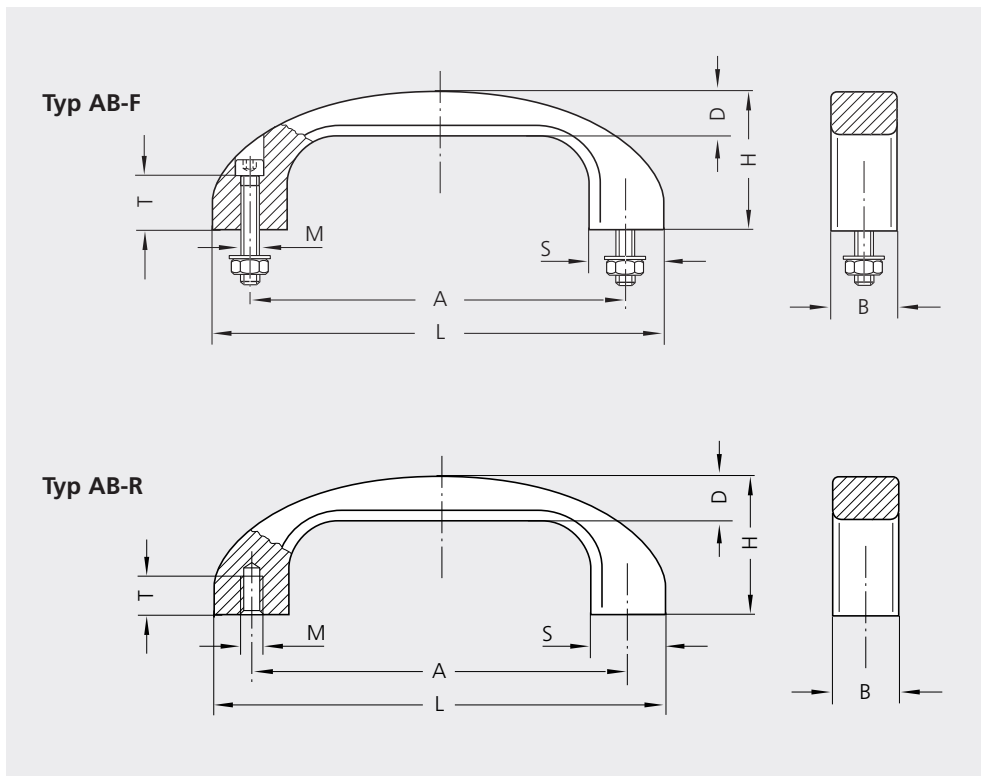

		Eloxalausführung Anodizing version		Pulverbeschichtet Powder coated						
		naturfarben natural colour	schwarz black	titanfarben* titanium colour*						
A	L	Bestell-Nr. Order no.	Bestell-Nr. Order no.	Bestell-Nr. Order no.	M	T	H	B	D	S
120	144	AB-22.F120.11	AB-22.F120.14	AB-22.F120.55	6 x 25	15	46	22	15	24
		AB-22.R120.11	AB-22.R120.14	AB-22.R120.55	6	12				
140	168	AB-25.F140.11	AB-25.F140.14	AB-25.F140.55	8 x 30	15	53	25	17	28
		AB-25.R140.11	AB-25.R140.14	AB-25.R140.55	8	15				

* Farbausführung siehe Seite 48-49
Colour version see page 48-49