


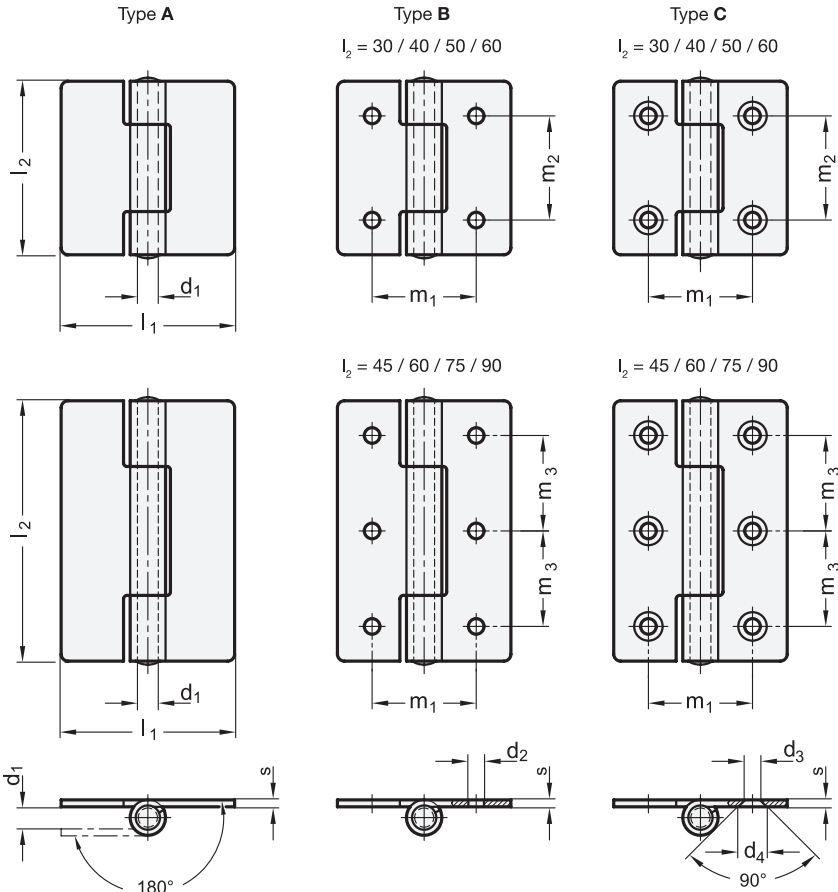

 Inox
Stainless
Steel

- 4 Type**
- A** without bores, for welding (only in Stainless Steel NI)
 - B** with bores for cylinder head screws / lens head screws
 - C** with bore for countersunk screws

2			3							
l ₁	l ₂		d ₁	d ₂	d ₃	d ₄	m ₁	m ₂	m ₃	s
30	30	45	3	3,2	4	6,4	18	18	16,5	1,5
40	40	60	4	4,2	5	8,3	25	25	22,5	2
50	50	75	6	5,2	5	8,3	30	30	27,5	2
60	60	90	6	5,2	5	8,3	36	36	33	2

Specification

- Steel
- only type B and C
- zinc plated, blue passivated
- Stainless Steel 304 all types
- Pin
- Stainless Steel AISI 304
- riveted
- Stainless Steel characteristics → Page 1489
- Load rating information → Page 1459
- RoHS compliant

Information

- Sheet metal hinges GN 136 are low-cost designs for low-load applications.
- see also
- List of hinge types → Page 956 ff.

How to order		1	Material
		2	l ₁
		3	l ₂
		4	Type

GN 136-NI-40-40-A