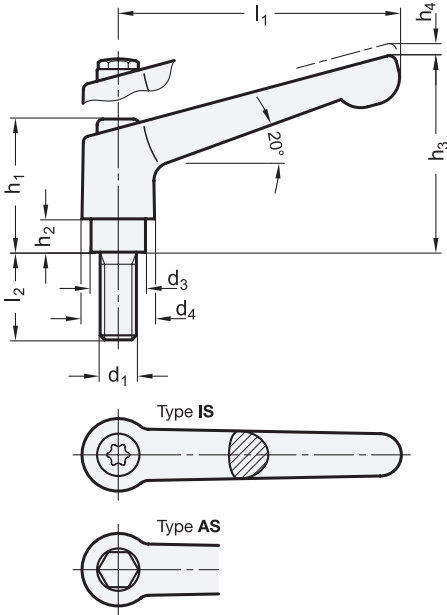


4 Type
AS with external hexagon
IS with internal hexalobular

1	2	3														
l ₁	d ₁			l ₂							d ₃	d ₄	h ₁	h ₂	h ₃	h ₄ Stroke
30	M 3	-		6	8	10	12	16	-	-	10	13	24,5	4	31	3,5
30	M 4	-		12	16	20	25	32	-	-	10	13	24,5	4	31	3,5
30	M 5	M 6		12	16	20	25	32	40	50	10	13	24,5	4	31	3,5
45	M 4	-		12	16	20	25	32	-	-	10	13	24,5	4	34	3,5
45	M 5	M 6		12	16	20	25	32	40	50	10	13	24,5	4	34	3,5
63	M 6	M 8		16	20	25	32	40	50	63	13,5	17,5	31	6,5	45	4
78	M 8	M 10		20	25	32	40	50	63	80	16	21	36	8	54	4
92	M 10	M 12		20	25	32	40	50	63	80	19	24	43	11	64	4

Specification

- **GN 300.5**
Handle
Stainless Steel-Precision casting
- AISI CF-8
- matt shot-blasted
- **GN 300.6**
Handle
Stainless Steel-Precision casting
- AISI CF-8
- electropolished
- Threaded stud
Stainless Steel AISI 303
- Retaining screw
Stainless Steel AISI 303
- Spring
Stainless Steel AISI 301
- *Stainless Steel characteristics → Page 1489*
- **RoHS compliant**

Information

Adjustable hand levers GN 300.5 with full Stainless Steel-Handle, correspond to applications where „agressive“ surrounding conditions are given, or where stainless steel materials are prescribed such as in food processing or chemical industry.

Retaining screws with hexagon head (Type AS) comply with the requirement „prevents water from accumulating“.

Adjustable hand levers have proved to be ideal whenever parts have to be clamped in a confined space or in a particular lever position. The centre insert is connected to the lever via serrations which can easily be disengaged.

How to order (matt shot-blasted)		1	l ₁
		2	d ₁
		3	l ₂
		4	Type
		GN300.5-63-M8-32-IS	

How to order (electropolished)		1	l ₁
		2	d ₁
		3	l ₂
		4	Type
		GN300.6-92-M12-50-AS	