


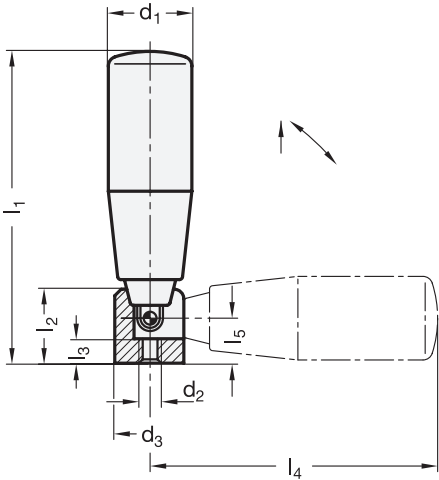

d ₁ GN 598.3	GN 598.5	d ₂	d ₃	l ₁ ≈	l ₂	l ₃	l ₄ ≈	l ₅
18	-	M 5	16	57	15	5	52	9,5
21	-	M 5	16	67	15	5	62	9,5
22	-	M 5	16	73	15	5	68	9,5
23	23	M 6	20	87	19,5	6	80	10,5
26	26	M 6	20	102	19,5	6	95	10,5
28	28	M 8	26	118	26	10	106	16

Specification

- Handle
Plastic
Duroplast (Phenolic PF)
 - temperature resistant up to 110 °C
 - black, shiny finish
 - revolving

- GN 598.3
Retractable mechanism steel
blackened

- GN 598.5
Retractable mechanism
Stainless Steel
 - Stud
AISI 303
 - Flat base
Sintered Steel AISI 316 L

- Stainless Steel characteristics → Page 1489
- Plastic characteristics → Page 1483
- RoHS-compliant

Information

Retractable handles GN 598.3 / GN 598.5 are suitable when the handle must be withdrawn during automatic operations.

see also...

- Safety retractable handles GN 798.7
(automatic return to the retracted position) → Page 45

How to order (Retractable mechanism steel)		1	Material
GN 598.3-KU-26		2	d ₁
How to order (Retractable mechanism St. Steel)		1	Material
GN 598.5-KU-23		2	d ₁