


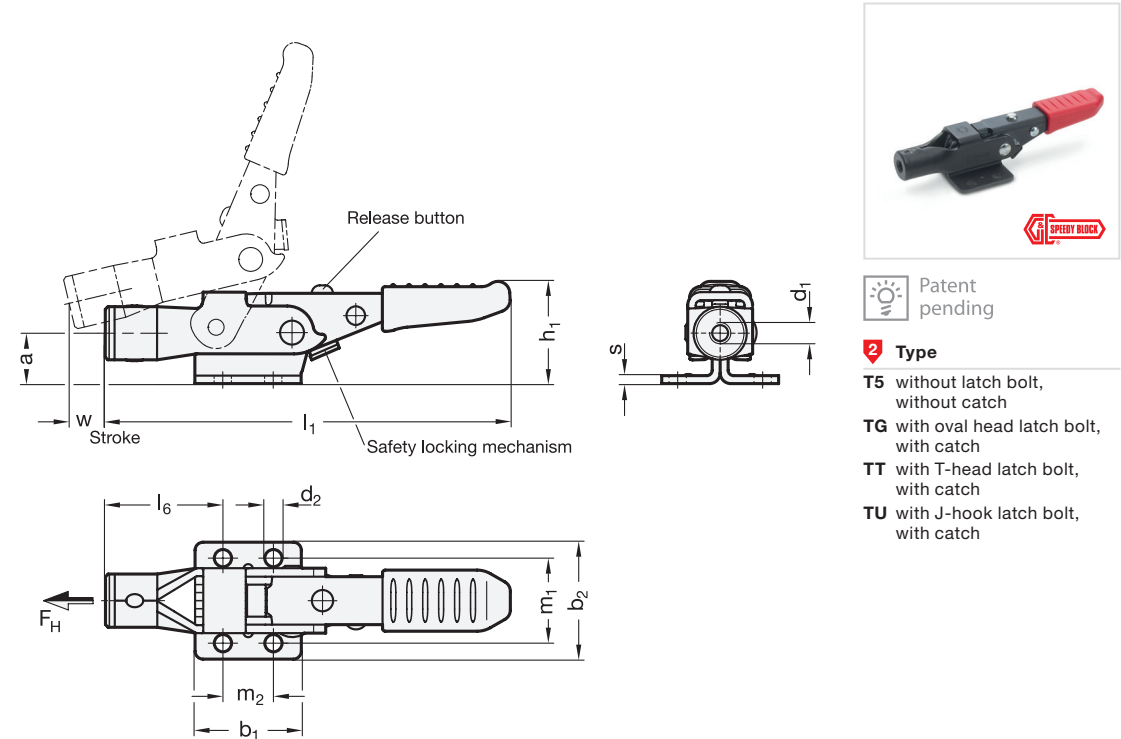

1

Size	FH in N Holding capacity	a	b ₁	b ₂	b ₃	b ₄	b ₅	b ₆	b ₇	d ₁	d ₂	d ₃	d ₄	d ₅	h ₁ ≈
160	1750	13	26	28	23	14	26	35	6,8	M 6	4,5	4,5	5,2	6	27
320	4000	19	40	44	34	18	35	38	10	M 8	6,7	6,7	7	8	38,5
700	7500	28	60	54	41	26	50	50	11	M 10	8,5	8,5	9	10	53

2

Size	h ₂	h ₃	l ₁ ≈	l ₂ ≈ Type TG	l ₃ ≈ Type TT	l ₄ ≈ Type TU	l ₅	l ₆	m ₁	m ₂	m ₃	m ₄	m ₅	s	w Stroke
160	20	20,5	103	55	55	54	28	30	19	16	16	14,3	25,4	2	8
320	30	28	153	76,5	76,5	76,5	34	44,5	32	19	19	22,3	25,4	3	13
700	40,5	39	222	95,5	93	92	42	51	38	41,5	31	25,4	31	3,5	19

Specification

- Parts in sheet metal
Case-hardened Steel C10
blackened
- Latch bolt
Steel St 32
blackened
- All moving parts
lubricated with special grease
- Solid moulded plastic handle sleeve
red, oil resistant
- RoHS compliant

Information

GN 853 latch type toggle clamps feature a locking mechanism which prevents an inadvertent or vibration-induced opening of the clamp.

Another benefit is the option of operating the clamp with one hand.

see also...

- Stainless Steel-Latch type toggle clamps GN 853 → Page 564

How to order	1	Size
	2	Type

GN853-320-TT