


Assembly examples

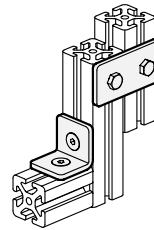

- 3 Type**
- F Shackle
- L Angle

4 Identification no.

- 1 with bore for countersunk screws DIN 7991
- 2 with bore without countersunk

1	2	2				
b	l₁ Type F	l₂ Type L	l₃	m	d	s
20	40	20	10	20	5,2	3
30	60	30	15	30	6,3	4
40	80	40	20	40	8,3	5
45	90	45	22,5	45	8,3	5

Specification

- Sheet steel
- zinc plated, blue passivated **ZB**
- plastic coated
- black, RAL 9005, textured finish **● SW**
- silver, RAL 9006, textured finish **● SR**
- RoHS compliant



Information

Angle pieces and shackles GN 967 are preferably used in connection with profile section systems. Square connections or connections with same contact area can so be realised in the smallest of spaces and with a high degree of stability.

Over and above the profile system configurations, the angle pieces and shackles can also be used for a wide variety of different fixing and retaining tasks, for instance in the design of jigs and fixtures.

In the version with identification no. 2 the drill holes are designed without countersunk hole to allow fixing with cylinder head screws, nuts or rivets.

Shackle	1	b
	2	l₁
	3	Type
	4	Identification no.
	5	Finish
		GN967-40-80-F-1-SW

Angle piece	1	b
	2	l₂
	3	Type
	4	Identification no.
	5	Finish
		GN967-30-30-L-1-SW