



Type A

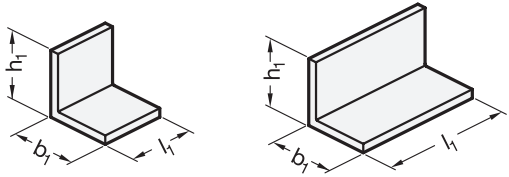

Type B

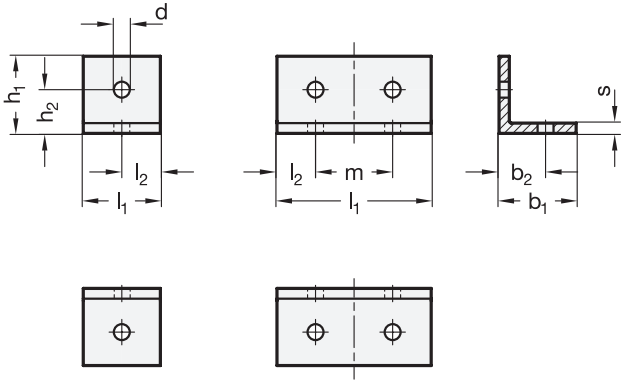

**5 Type**

- A** without bores  
**B** with bores



<b>2</b> $h_1$	<b>3</b> $b_1$	<b>4</b> $l_1$	$b_2$	$d$	$h_2$	$l_2$	$m$	$s$
30	30	30	18	6,2	18	15	-	4
30	30	60	18	6,2	18	15	30	4
40	40	40	24	8,2	24	20	-	5
40	40	80	24	8,2	24	20	40	5
50*	50	50	30	10,2	30	25	-	6
50*	50	100	30	10,2	30	25	50	6

\* only available in version ALM

**Specification**

- Structural Steel  
drawn, with sharp edges  
blackened
- Aluminum  
pressed  
matt, ground
- RoHS compliant



**Information**

**STB**

GN 970 installation brackets are used universally for right-angle connecting and fastening of, e.g. base plates or covers.

Type A allows for the use of drilling templates specific to the application as well as fastening by welding.

Type B installation brackets have 2 or 4 holes depending on the length  $l_1$ .

see also...

- Angle pieces, Shackles GN 967 → New products

**ALM**

**How to order**

<b>1</b>	<b>Material</b>
<b>2</b>	$h_1$
<b>3</b>	$b_1$
<b>4</b>	$l_1$
<b>5</b>	<b>Type</b>

**GN970-STB-40-60-80-B**