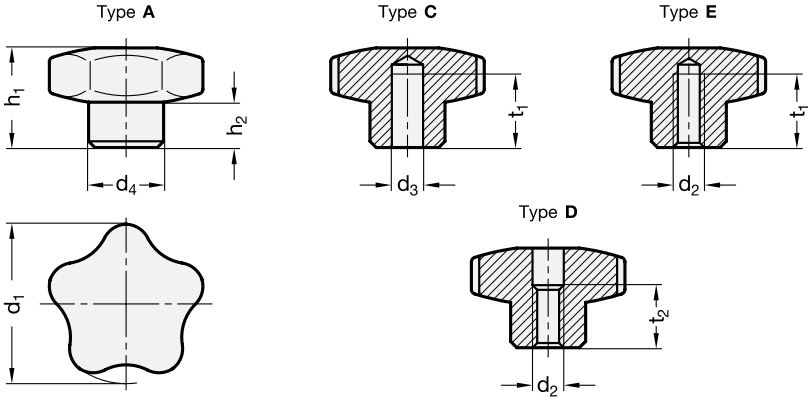


- 3 Type**
- A casting only (unmachined)
 - C with blind bore H7
 - D with threaded through bore
 - E with threaded blind bore

1 d₁	2 d₂ Thread Type E	2 Type D Type E	2 d₃ H7 Bore Type C	d₄ -0,5	h₁ -1 Type A	Type C Type D Type E	h₂ ≈	t₁ min.	t₂
40	M 6	M 8	B 8	15	25	25	12,5	15	15
50	M 8	M 10	B 10	19	32	32	16	18	20
60	M 10	M 12	B 12	21	40	40	20	22	26
70	M 12	M 16	B 16	26	46	46	23	28	32

Specification

- Aluminium
 - matt finish (ground) **MT**
 - flash mark not visible
 - polished **PL**
- Type **A** (without bore)
only available with a matt finish (MT)
- Cross hole GN 110 → Page 1127
- ISO-Fundamental Tolerances → Page 1132
- RoHS compliant

Information

Star knobs GN 5336 are forged, therefore a close grain structure is maintained providing a high tensile strength and a smooth surface.

Original ELESA design, now produced in metal in agreement with ELESA s.p.a.

How to order		1	d₁
		2	d₂ (d₃)
		3	Type
		4	Finish
GN 5336-50-M10-E-MT			