

**AT-05 Series**  
**A-15**

平面鉸鏈 *Butt Hinge*

SUS304

RoHS




AT-0510



AS-1510, A-1510



AT-0511

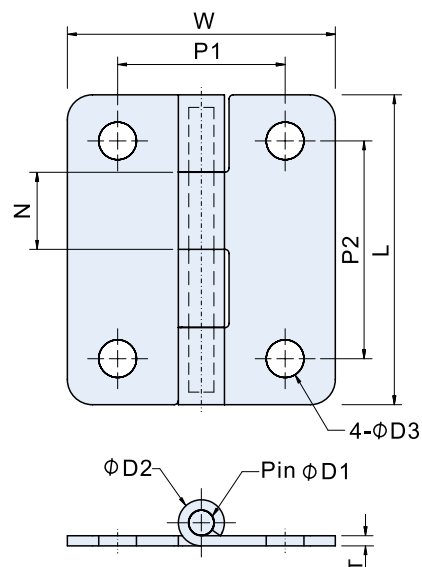

SPECIFICATIONS:

Unit:mm

| 產品編號<br>Item No. | 材質<br>Material | 表面處理             | 尺寸 Dimensions |    |     |    |      |     |     |     |     | 重量<br>Weight (g) |
|------------------|----------------|------------------|---------------|----|-----|----|------|-----|-----|-----|-----|------------------|
|                  |                |                  | L             | W  | T   | P1 | P2   | D1  | D2  | D3  | N   |                  |
| AT-0510          | SPCC           | 鍍鋅 Zinc plated   | 37            | 32 | 1.2 | 20 | 26   | 3   | 5.6 | 4.5 | 9   | 15.6             |
| AT-0511          | SPCC           | 材料本質 Natural     |               |    |     |    |      |     |     |     |     | 16               |
| A-1510           | SUS430         | 亮面               | 38.2          | 31 | 0.9 | 19 | 25.4 | 2.3 | 4.3 | 4.0 | 6.3 | 10.8             |
| AS-1510          | SUS304         | Vibration ground |               |    |     |    |      |     |     |     |     | 11.0             |


**AS-1520**  
**AT-1520**

平面鉸鏈 *Butt Hinge*

SUS304

RoHS

AS-1520  
AT-1520

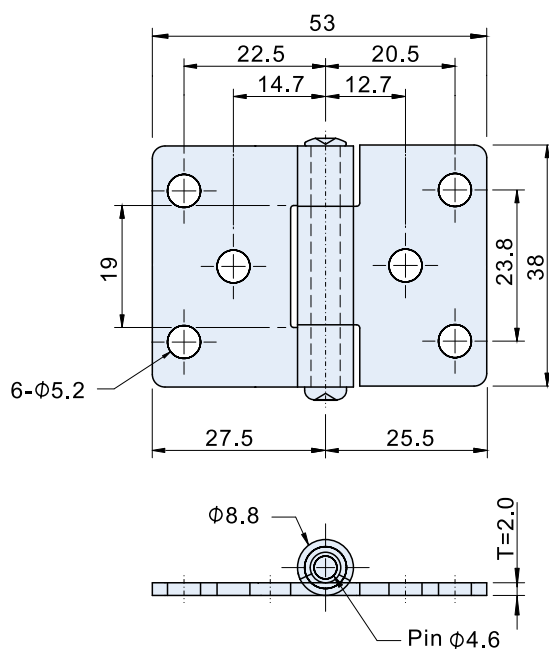

SPECIFICATION:

Unit:mm

| 產品編號<br>Item No. | 材質<br>Material | 表面處理<br>Finish      | 重量<br>Weight(g) |
|------------------|----------------|---------------------|-----------------|
| AS-1520          | SUS304         | 亮面 Vibration ground | 40              |
| AT-1520          | SPCC           | 鍍鋅 Zinc plated      |                 |