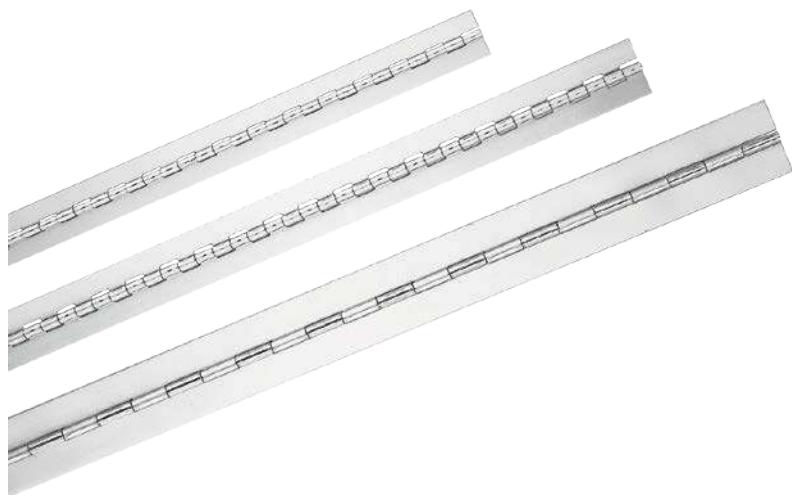


材質與表面處理

- AS：不銹鋼(SUS304)·材料本質(亮面)。
 ■ A：鐵材(SPCC)·材料本質。

MATERIAL AND FINISH

- AS:Stainless steel (SUS304), Natural (Bright).
 ■ A :Cold-rolled steel (SPCC), Natural.

SPECIFICATION:

Unit:mm

產品編號 Item No.	重量 Weight(kg)	產品編號 Item No.	重量 Weight(kg)	尺寸 Dimensions					
				L	W	T	D1	D2	N
SUS304		SPCC							
AS-102610	0.29	A-102610	0.29	1000	26	1	2.5	4.6	10
AS-102612	0.35	A-102612	0.35	1200					
AS-123210	0.42	A-123210	0.43	1000	32	1.2	3	5.6	12.5
AS-123212	0.51	A-123212	0.51	1200					
AS-123215	0.64	A-123215	0.64	1500					
AS-123218	0.77	A-123218	0.77	1800					
AS-123810	0.48	A-123810	0.46	1000	38	1.2	3	5.6	12.5
AS-123812	0.57	A-123812	0.54	1200					
AS-123815	0.73	A-123815	0.73	1500					
AS-123818	0.84	A-123818	0.87	1800					
AS-125010	0.60	A-125010	0.59	1000	50	1.2	3	5.6	12.5
AS-125012	0.71	A-125012	0.72	1200					
AS-125015	0.89	A-125015	0.88	1500					
AS-125018	1.06	A-125018	1.07	1800					
AS-153810	0.61	A-153810	0.62	1000	38	1.5	3.5	6.7	12.5
AS-153812	0.75	A-153812	0.74	1200					
AS-153815	0.93	A-153815	0.93	1500					
AS-153818	1.11	A-153818	1.12	1800					
AS-155010	0.76	A-155010	0.76	1000	50	1.5	3.5	6.7	12.5
AS-155012	0.92	A-155012	0.91	1200					
AS-155015	1.16	A-155015	1.14	1500					
AS-155018	1.37	A-155018	1.38	1800					
AS-205110	1.04	A-205110	1.06	1016 (40")	51 (2")	2	3.8	8.1	25.4 (1")
AS-205112	1.30	A-205112	1.27	1219 (48")					
AS-205115	1.61	A-205115	1.59	1524 (60")					
AS-205118	1.88	A-205118	1.9	1829 (72")					
		AT-307610	2.59	1067 (40")	76 (3")	3	6	12.4	38.1 (1.5")
		AT-307612	2.95	1219 (48")					
		AT-307615	3.66	1524 (60")					
		AT-307618	4.43	1829 (72")					