
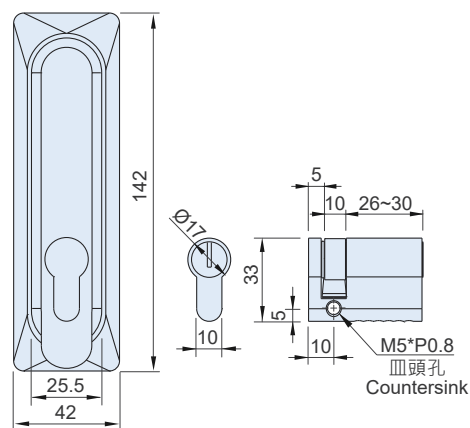
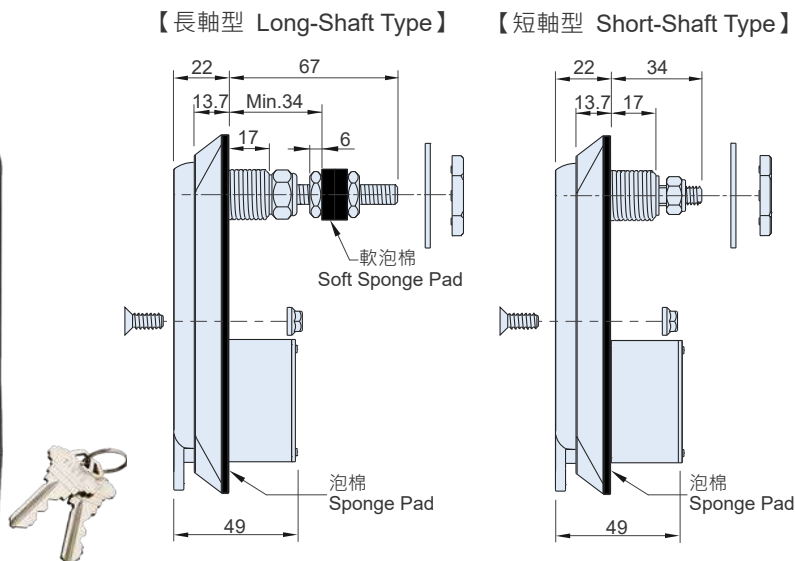


左開多點連桿裝配示意圖
Installation

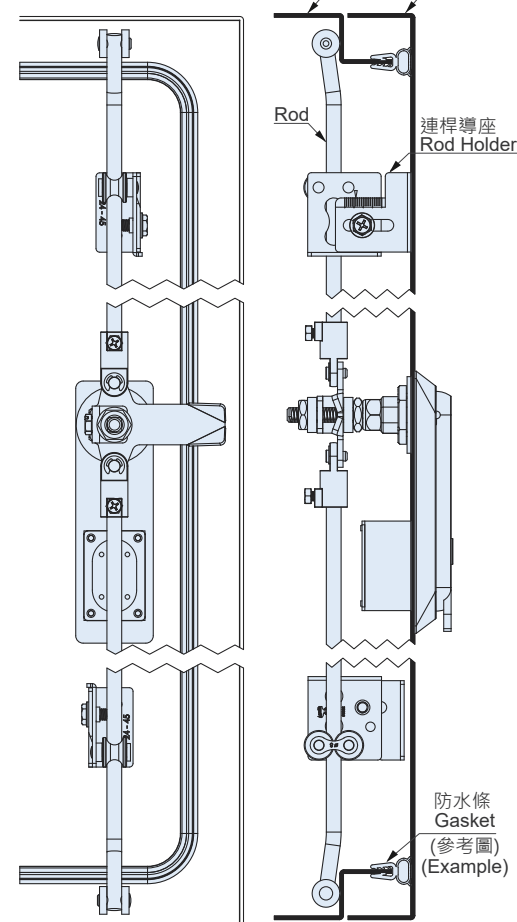

材質與表面處理

- 本體與掀把：鋅合金，電著黑、鍍鉻。
- 軸心：鐵，鍍鎳。

特徵

- 使用天地栓連桿讓門框不易搖動
- 適用板厚：5mm以內。
- 防塵、防水(IP65)。

MATERIAL AND FINISH

- Body and Lever: Die-cast Zinc, Chrome plated or Black coated.
- Shaft: Steel, Nickel plated.
- Applicable Key: Bronze, chrome plated.

FEATURES

- With pawl attaching rod system, the door frame will not shake.
- Max. door panel thickness: 5mm.
- Dust-resistant and waterproof (IP65).

SPECIFICATION:

Unit:mm

產品編號 Item No.			軸心型式 Shaft Type	重量 Weight (g)
鍍鉻 Chrome plated	本體黑色、掀把鍍鉻 Black Body, Chrome Lever	電著黑 Black coated		
BZ-04217	BZ-04218	BZ-04219	短軸型 Short Shaft	559
BZ-04237	BZ-04238	BZ-04239	長軸型 Long Shaft	595

備註：短軸型不適用天地栓連桿。本產品不含檔片、天地栓連桿及連桿導座，請參考右頁選配。

Remark: Rod Latch System does not apply to the Short Shaft Multi-point Latching System.

The latch is without pawl, rod latch system, and rod holder. Please refer to the right page.