

CS-08300 / CT-08300

CS-08302 / CT-08302





 
 



CS-08303



CS-08300 / CT-08300

CS-08302 / CT-08302

CS-08303

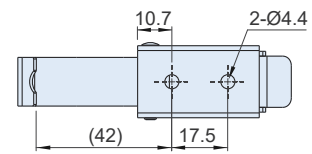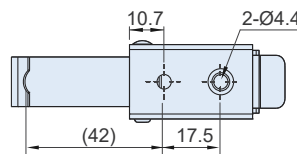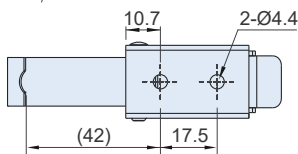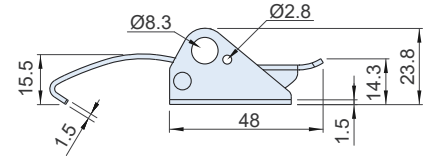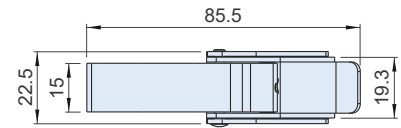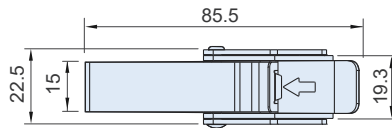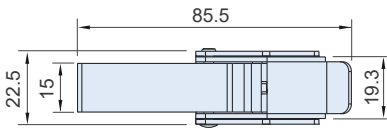

- 特徵**
- 扣鉤特殊設計，可以無需鉤座而直接扣住物件或螺絲。
  - CS(T)-08302的輔助鎖扣提供額外防護，避免嚴重震動彈開、意外開啟、衝擊載荷。
  - CS-08303有兩種鎖固方式：
    - 可插栓線使物件更牢固
    - 可用鋼掛鎖阻絕彈開可能性及增加安全性
- FEATURES**
- Special hook design can easily and directly lock or hooked screws without latch keeper.
  - CS(T)-08302: Make use of assistance latches and locks to do an additional protection, avoid seriously vibrating, suddenly opened, and loading huge capacity.
  - CS-08303: Two ways for lock:
    - Can use tie wire to make sure the goods can be more stable.
    - Standard lock-hole available padlocks to prevent from the accident.

SPECIFICATION:

Unit:mm

產品編號 Item No.	主體 Body		扣鉤 Hook		彈片 Lock		引張荷重 Load capacity (kgf)	重量 Weight (g)
	材質 Material	表面處理 Finish	材質 Material	表面處理 Finish	材質 Material	表面處理 Finish		
CS-08300	SUS304	震動亮面 Vibration ground	SUS420	震動亮面+透明漆 Vibration ground + coating			2mm=50kgf	43
CT-08300	SPCC	鍍鋅 Zinc plated	SPCC	鍍鋅 Zinc plated				
CS-08302	SUS304	震動亮面 Vibration ground	SUS420	震動亮面+透明漆 Vibration ground + coating	SUS301	震動亮面 Vibration ground	2mm=50kgf	44.7
CT-08302	SPCC	鍍鋅 Zinc plated	SPCC	鍍鋅 Zinc plated				
CS-08303	SUS304	震動亮面 Vibration ground	SUS420	震動亮面+透明漆 Vibration ground + coating				50.6