


DVC.1

Code	Description	D	L	d	d ₁	l	Max load [N]	Max. deflection [mm]	Stiffness [N/mm]
433201	DVC.1-10-4,5-8-M4-10-40	10	8	M4	4,5	10	43	2	22
433001	DVC.1-10-4,5-8-M4-10-55	10	8	M4	4,5	10	80	2	40
433401	DVC.1-10-4,5-8-M4-10-70	10	8	M4	4,5	10	105	2	53
433206	DVC.1-10-8-10-M4-10-40	10	10	M4	8	10	37	2.5	15
433006	DVC.1-10-8-10-M4-10-55	10	10	M4	8	10	69	2.5	28
433406	DVC.1-10-8-10-M4-10-70	10	10	M4	8	10	98	2.5	39
433211	DVC.1-15-8,5-15-M4-10-40	15	15	M4	8,5	10	113	3.75	30
433011	DVC.1-15-8,5-15-M4-10-55	15	15	M4	8,5	10	154	3.75	41
433411	DVC.1-15-8,5-15-M4-10-70	15	15	M4	8,5	10	207	3.75	55
433216	DVC.1-15-12-15-M4-10-40	15	15	M4	12	10	121	3.75	32
433016	DVC.1-15-12-15-M4-10-55	15	15	M4	12	10	163	3.75	43
433416	DVC.1-15-12-15-M4-10-70	15	15	M4	12	10	221	3.75	59
433231	DVC.1-20-14-15-M6-18-40	20	15	M6	14	18	211	3.75	56
433031	DVC.1-20-14-15-M6-18-55	20	15	M6	14	18	273	3.75	73
433431	DVC.1-20-14-15-M6-18-70	20	15	M6	14	18	325	3.75	87
433233	DVC.1-20-14-19-M6-18-40	20	19	M6	14	18	193	4.75	41
433033	DVC.1-20-14-19-M6-18-55	20	19	M6	14	18	238	4.75	50
433433	DVC.1-20-14-19-M6-18-70	20	19	M6	14	18	302	4.75	64
433235	DVC.1-20-14-20-M6-18-40	20	20	M6	14	18	191	5	38
433035	DVC.1-20-14-20-M6-18-55	20	20	M6	14	18	231	5	46
433435	DVC.1-20-14-20-M6-18-70	20	20	M6	14	18	300	5	60
433241	DVC.1-21-16-22-M6-18-40	21	22	M6	16	18	205	5.5	37
433041	DVC.1-21-16-22-M6-18-55	21	22	M6	16	18	268	5.5	49
433441	DVC.1-21-16-22-M6-18-70	21	22	M6	16	18	315	5.5	57
433221	DVC.1-20-12-30-M6-18-40	20	30	M6	12	18	126	7.5	17
433021	DVC.1-20-12-30-M6-18-55	20	30	M6	12	18	194	7.5	26
433421	DVC.1-20-12-30-M6-18-70	20	30	M6	12	18	217	7.5	29
433237	DVC.1-20-14-30-M6-18-40	20	30	M6	14	18	475	7.5	63
433037	DVC.1-20-14-30-M6-18-55	20	30	M6	14	18	202	7.5	27
433437	DVC.1-20-14-30-M6-18-70	20	30	M6	14	18	301	7.5	40
433251	DVC.1-25-18-20-M6-18-40	25	20	M6	18	18	539	5	108
433051	DVC.1-25-18-20-M6-18-55	25	20	M6	18	18	887	5	177
433451	DVC.1-25-18-20-M6-18-70	25	20	M6	18	18	1332	5	266
433256	DVC.1-25-20-20-M6-18-40	25	20	M6	20	18	560	5	112
433056	DVC.1-25-20-20-M6-18-55	25	20	M6	20	18	902	5	180
433456	DVC.1-25-20-20-M6-18-70	25	20	M6	20	18	1380	5	276
433266	DVC.1-30-22-20-M8-20-40	30	20	M8	22	20	738	5	148
433066	DVC.1-30-22-20-M8-20-55	30	20	M8	22	20	1087	5	217
433466	DVC.1-30-22-20-M8-20-70	30	20	M8	22	20	2005	5	401
433261	DVC.1-30-18-25-M8-20-40	30	25	M8	18	20	436	6.25	70
433061	DVC.1-30-18-25-M8-20-55	30	25	M8	18	20	671	6.25	107
433461	DVC.1-30-18-25-M8-20-70	30	25	M8	18	20	1342	6.25	215
433276	DVC.1-35-31-15-M8-20-40	35	15	M8	31	20	1120	3.75	299
433076	DVC.1-35-31-15-M8-20-55	35	15	M8	31	20	2097	3.75	559
433476	DVC.1-35-31-15-M8-20-70	35	15	M8	31	20	3215	3.75	857

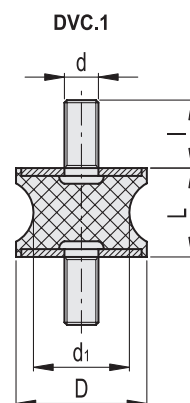

DVC.1 - 10 - 4.5 - 8 - M4 - 10 - 55
D d₁ L d l Shore A

