

折疊式電木 / 不鏽鋼安全把手 HL / HL-A / HL-ST / HL-AST 系列

Retractable / Stainless-plant Handles

# HL / HL-A / HL-ST / HL-AST


series

把手材質: 電木  
Handle material: Phenol resin



HL / HL-ST

HL-A / HL-AST

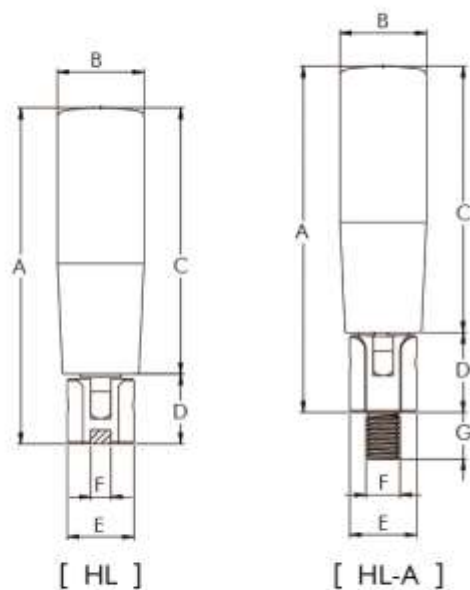

尺寸單位 Unit : mm

型號 Model No.		A	B	C	D	E	F	G	毛重 G.W.
電鍍 Chromium	不鏽鋼 Stainless								
HL-40	HL-40-ST	57	19	40	17	16	M4	-	0.04kg
HL-50	HL-50-ST	67	21	50	17	16	M4	-	0.05kg
HL-65	HL-65-ST	86	23	65	21	20	M6	-	0.1 kg
HL-80	HL-80-ST	101	26	80	21	20	M6	-	0.12kg
HL-90	HL-90-ST	111	28	90	21	20	M6	-	0.13kg
HL-65A	HL-65A-ST	89	23	65	24	20	M10	14	0.11kg
HL-80A	HL-80A-ST	104	26	80	24	20	M10	14	0.13kg
HL-90A	HL-90A-ST	114	28	90	24	20	M10	14	0.14kg