


Hexagon nuts thin DIN 439

Item description/product images

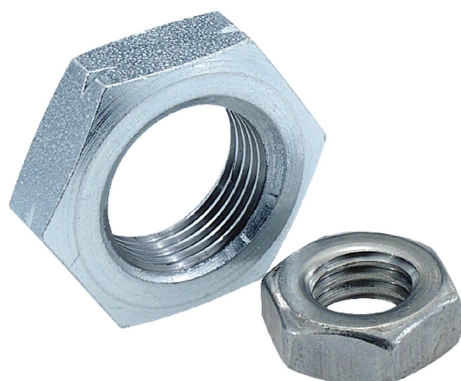

Description

Material:

Steel, stainless steel A2 or stainless steel A4.

Version:

Steel grade 04, electro zinc-plated or black oxidised.


Stainless steel A2, bright.

Stainless steel A4, bright.

Note:

These hexagon nuts are used in screw connections exposed to limited loads, e.g. as a locknut for clevis joints or rod ends.

Drawings

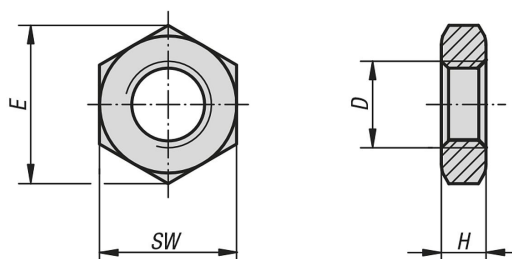

Overview of items

Hexagon nuts thin DIN 439

Order No.	Main material	Surface finish body	Version 2	D	E	H	SW
K0700.006	steel	galvanised	RH thread	M6X0,75	11,05	3,2	10
K0700.008	steel	galvanised	RH thread	M8X1	14,38	4	13
K0700.05	steel	galvanised	RH thread	M5	8,79	2,7	8
K0700.06	steel	galvanised	RH thread	M6	11,05	3,2	10
K0700.061	steel	galvanised	LH thread	M6	11,05	3,2	10
K0700.08	steel	galvanised	RH thread	M8	14,38	4	13
K0700.081	steel	galvanised	LH thread	M8	14,38	4	13
K0700.10	steel	galvanised	RH thread	M10	18,9	5	17
K0700.101	steel	galvanised	LH thread	M10	18,9	5	17
K0700.103	steel	galvanised	RH thread	M10X1	18,9	5	17
K0700.1031	steel	galvanised	LH thread	M10X1	18,9	5	17
K0700.104	steel	galvanised	RH thread	M10X1,25	18,9	5	17
K0700.1041	steel	galvanised	LH thread	M10X1,25	18,9	5	17
K0700.12	steel	galvanised	RH thread	M12	21,1	6	19
K0700.121	steel	galvanised	LH thread	M12	21,1	6	19
K0700.123	steel	galvanised	RH thread	M12X1,25	21,1	6	19
K0700.1231	steel	galvanised	LH thread	M12X1,25	21,1	6	19
K0700.124	steel	galvanised	RH thread	M12X1,5	21,1	6	19
K0700.1241	steel	galvanised	LH thread	M12X1,5	21,1	6	19
K0700.16	steel	galvanised	RH thread	M16	26,76	8	24
K0700.161	steel	galvanised	LH thread	M16	26,76	8	24
K0700.163	steel	galvanised	RH thread	M16x1,5	26,76	8	24
K0700.183	steel	galvanised	RH thread	M18x1,5	29,56	9	27
K0700.203	steel	galvanised	RH thread	M20X1,5	32,95	10	30
K0700.2031	steel	galvanised	LH thread	M20X1,5	32,95	10	30
K0700.223	steel	galvanised	RH thread	M22x1,5	36,9	10	32