

Levelling feet steel or stainless steel Form B

Item description/product images

Description


Material:

Foot plate and threaded spindle steel or stainless steel.
Rubber support (NBR) 80 Shore.

Version:

Foot plate and threaded spindle electro zinc-plated steel.
Foot plate polished stainless steel.
Threaded spindle bright stainless steel.
Rubber support, vulcanised, black.

Drawings

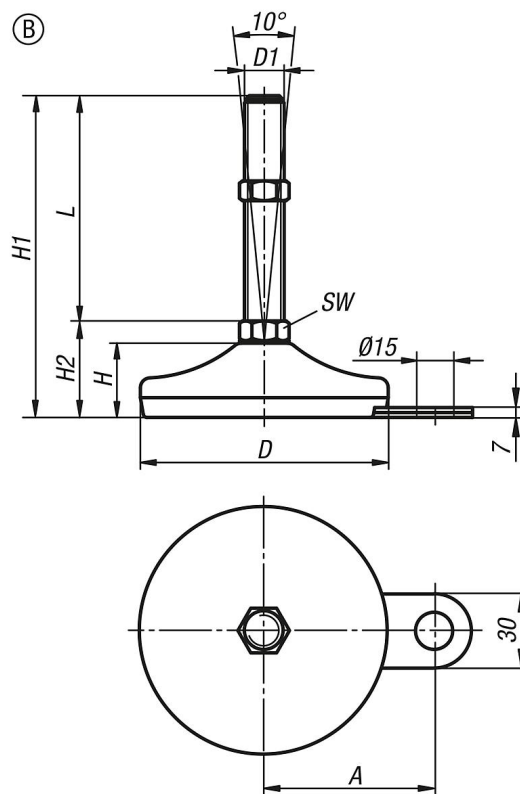

Overview of items

Order No.	Form	Main material	A	D	D1	H	H1	H2	SW	L	Load rating max. kN (static load only)
K0739.2106010X50	B	steel	45	60	M10	22	82	32	14	50	7
K0739.2106010X100	B	steel	45	60	M10	22	132	32	14	100	7
K0739.2106012X50	B	steel	45	60	M12	22	82	32	14	50	7
K0739.2106012X100	B	steel	45	60	M12	22	132	32	14	100	7
K0739.2106012X150	B	steel	45	60	M12	22	182	32	14	150	7
K0739.2108010X50	B	steel	54	80	M10	25	85	35	14	50	10
K0739.2108010X100	B	steel	54	80	M10	25	135	35	14	100	10
K0739.2108012X50	B	steel	54	80	M12	25	85	35	14	50	10
K0739.2108012X100	B	steel	54	80	M12	25	135	35	14	100	10
K0739.2108012X150	B	steel	54	80	M12	25	185	35	14	150	10