

Thrust screws with fixed T-bar, DIN 6304

Item description/product images




Description

Material:
Steel.

Version:
Black oxidised. Thrust pin hardened.

Note:
For fixed spindles, the spindle is press fitted.

Drawings

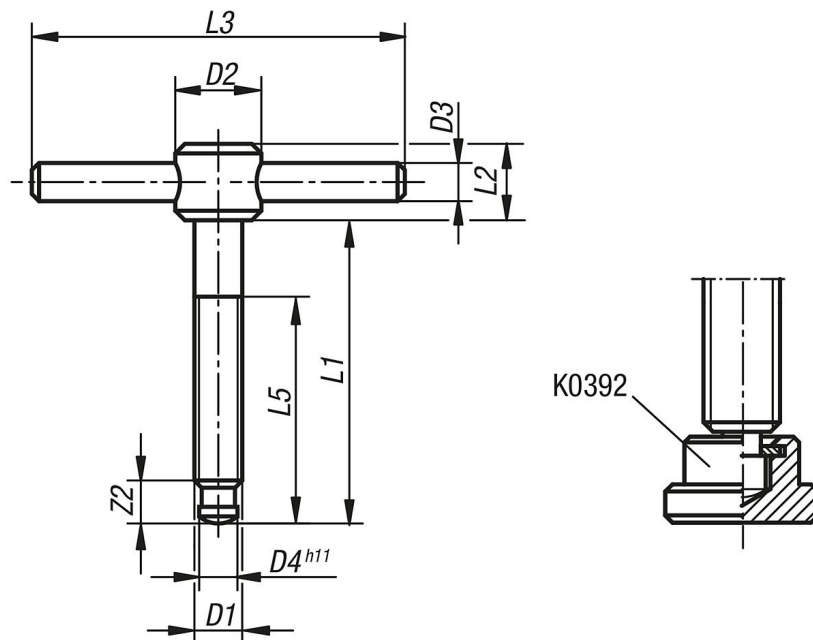

Overview of items

Order No.	Version 1	D1	D2	D3	D4	L1	L2	L3	L5	Z2
K0756.106X40	fixed t-bar	M6	12	5	4,5	40	10	50	30	6
K0756.106X50	fixed t-bar	M6	12	5	4,5	50	10	50	40	6
K0756.108X50	fixed t-bar	M8	14	6	6	50	12	60	35	7,5
K0756.108X60	fixed t-bar	M8	14	6	6	60	12	60	45	7,5
K0756.110X60	fixed t-bar	M10	18	8	8	60	14	80	40	9
K0756.110X70	fixed t-bar	M10	18	8	8	70	14	80	50	9
K0756.112X70	fixed t-bar	M12	20	10	8	70	18	100	50	10
K0756.112X80	fixed t-bar	M12	20	10	8	80	18	100	60	10
K0756.116X75	fixed t-bar	M16	24	12	12	75	20	120	55	12
K0756.116X90	fixed t-bar	M16	24	12	12	90	20	120	70	12
K0756.116X110	fixed t-bar	M16	24	12	12	110	20	120	90	12
K0756.120X75	fixed t-bar	M20	30	16	15,5	75	28	140	55	14
K0756.120X90	fixed t-bar	M20	30	16	15,5	90	28	140	70	14
K0756.120X110	fixed t-bar	M20	30	16	15,5	110	28	140	90	14