


Hexagon head bolts DIN 933/ISO 4017, stainless steel

Item description/product images

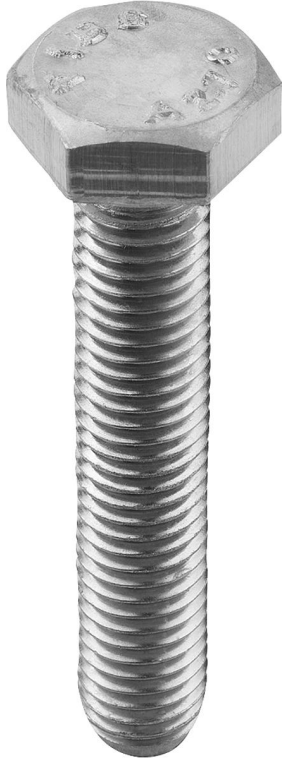

Description

Material:


Stainless steel A2 or stainless steel A4.

Version:

Stainless steel A2-70, bright.

Stainless steel A4-70, bright.

Drawings

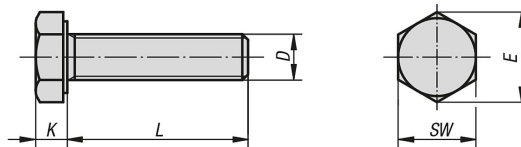

Overview of items

Order No.	Main material	Grade	Surface finish body	D	L	SW	E	K
K0871.104X10	stainless steel A2	70	bright	M4	10	7	7,66	2,8
K0871.104X12	stainless steel A2	70	bright	M4	12	7	7,66	2,8
K0871.104X16	stainless steel A2	70	bright	M4	16	7	7,66	2,8
K0871.104X18	stainless steel A2	70	bright	M4	18	7	7,66	2,8
K0871.104X20	stainless steel A2	70	bright	M4	20	7	7,66	2,8
K0871.104X25	stainless steel A2	70	bright	M4	25	7	7,66	2,8
K0871.105X10	stainless steel A2	70	bright	M5	10	8	8,79	3,5
K0871.105X12	stainless steel A2	70	bright	M5	12	8	8,79	3,5
K0871.105X16	stainless steel A2	70	bright	M5	16	8	8,79	3,5
K0871.105X18	stainless steel A2	70	bright	M5	18	8	8,79	3,5
K0871.105X20	stainless steel A2	70	bright	M5	20	8	8,79	3,5
K0871.105X25	stainless steel A2	70	bright	M5	25	8	8,79	3,5
K0871.105X30	stainless steel A2	70	bright	M5	30	8	8,79	3,5
K0871.105X35	stainless steel A2	70	bright	M5	35	8	8,79	3,5
K0871.105X40	stainless steel A2	70	bright	M5	40	8	8,79	3,5
K0871.106X10	stainless steel A2	70	bright	M6	10	10	11,05	4