

Drill bushes cylindrical, DIN 179, Form A

Item description/product images



Description

Material:

Special low carbon steel

Version:

Hardened to 740 ± 80 HV 10 and ground.

Note:

From diameter D1 over 15 mm size increases are 0.5 mm.


Drawing reference:

Form A: hole rounded one end

Form B: hole rounded both ends

1) Chamfer for insert

Drawings

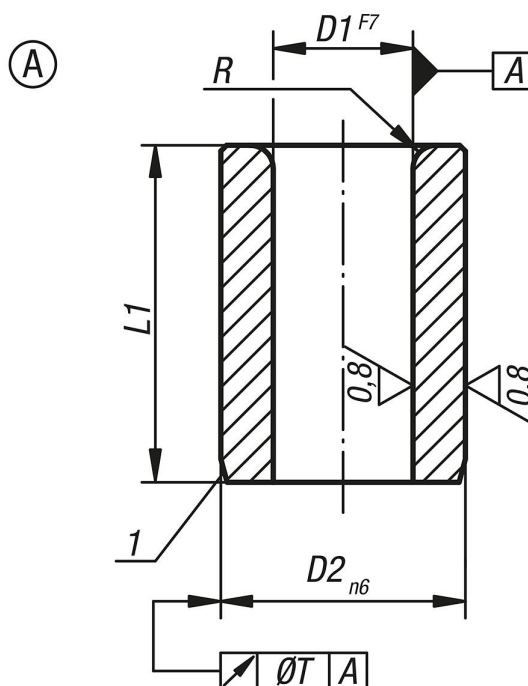

Overview of items

Order No.	Form	D1	D2	L1	Product type	R	T
K1021.A0040X06	A	0,4	3	6	short	1	0,01
K1021.A0060X06	A	0,6	3	6	short	1	0,01
K1021.A0070X06	A	0,7	3	6	short	1	0,01
K1021.A0080X06	A	0,8	3	6	short	1	0,01
K1021.A0090X06	A	0,9	3	6	short	1	0,01
K1021.A0090X09	A	0,9	3	9	medium	1	0,01
K1021.A0100X06	A	1	3	6	short	1	0,01
K1021.A0100X09	A	1	3	9	medium	1	0,01
K1021.A0110X06	A	1,1	4	6	short	1	0,01
K1021.A0110X09	A	1,1	4	9	medium	1	0,01