

Drill bushes cylindrical, DIN 179, Form B

Item description/product images



Description

Material:

Special low carbon steel

Version:

Hardened to 740 ±80 HV 10 and ground.

Note:

From diameter D1 over 15 mm size increases are 0.5 mm.


Drawing reference:

Form A: hole rounded one end

Form B: hole rounded both ends

1) Chamfer for insert

Drawings

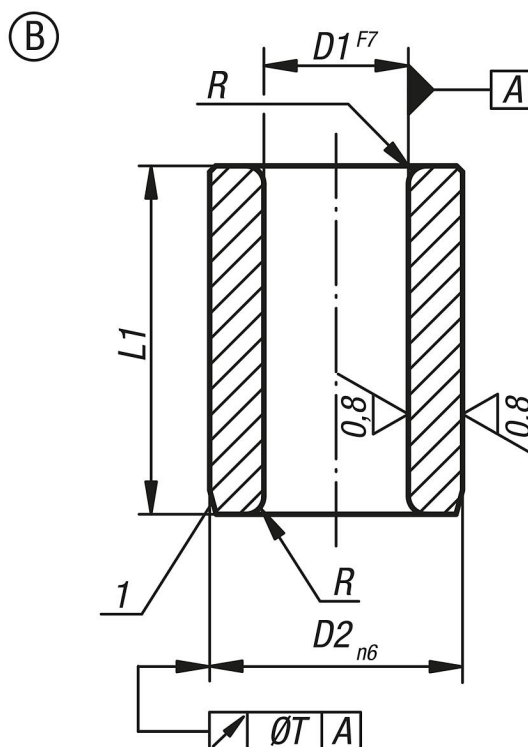

Overview of items

Order No.	Form	D1	D2	L1	Product type	R	T
K1021.B0060X06	B	0,6	3	6	short	1	0,01
K1021.B0070X06	B	0,7	3	6	short	1	0,01
K1021.B0080X06	B	0,8	3	6	short	1	0,01
K1021.B0090X06	B	0,9	3	6	short	1	0,01
K1021.B0090X09	B	0,9	3	9	medium	1	0,01
K1021.B0100X06	B	1	3	6	short	1	0,01
K1021.B0100X09	B	1	3	9	medium	1	0,01
K1021.B0110X06	B	1,1	4	6	short	1	0,01
K1021.B0110X09	B	1,1	4	9	medium	1	0,01