

# Hexagon socket button head screws EN ISO 7380-1, Form A

## Item description/product images



### Description

#### Material:

Steel, stainless steel A2 or stainless steel A4.


#### Version:

Steel grade 10.9, bright (black) or electro zinc-plated.

Stainless steel A2-70, bright.

Stainless steel A4-70, bright.

## Drawings

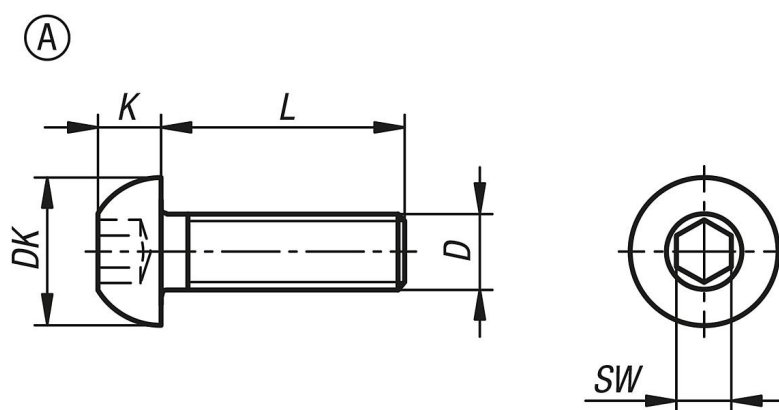

## Overview of items

| Order No.     | Form | Main material | Surface finish body | Grade | D  | L  | DK   | K    | SW  |
|---------------|------|---------------|---------------------|-------|----|----|------|------|-----|
| K1796.1303X8  | A    | steel         | bright (black)      | 10.9  | M3 | 8  | 5,7  | 1,65 | 2   |
| K1796.1303X10 | A    | steel         | bright (black)      | 10.9  | M3 | 10 | 5,7  | 1,65 | 2   |
| K1796.1303X12 | A    | steel         | bright (black)      | 10.9  | M3 | 12 | 5,7  | 1,65 | 2   |
| K1796.1303X16 | A    | steel         | bright (black)      | 10.9  | M3 | 16 | 5,7  | 1,65 | 2   |
| K1796.1303X20 | A    | steel         | bright (black)      | 10.9  | M3 | 20 | 5,7  | 1,65 | 2   |
| K1796.1304X8  | A    | steel         | bright (black)      | 10.9  | M4 | 8  | 7,6  | 2,2  | 2,5 |
| K1796.1304X10 | A    | steel         | bright (black)      | 10.9  | M4 | 10 | 7,6  | 2,2  | 2,5 |
| K1796.1304X12 | A    | steel         | bright (black)      | 10.9  | M4 | 12 | 7,6  | 2,2  | 2,5 |
| K1796.1304X16 | A    | steel         | bright (black)      | 10.9  | M4 | 16 | 7,6  | 2,2  | 2,5 |
| K1796.1304X20 | A    | steel         | bright (black)      | 10.9  | M4 | 20 | 7,6  | 2,2  | 2,5 |
| K1796.1304X25 | A    | steel         | bright (black)      | 10.9  | M4 | 25 | 7,6  | 2,2  | 2,5 |
| K1796.1304X30 | A    | steel         | bright (black)      | 10.9  | M4 | 30 | 7,6  | 2,2  | 2,5 |
| K1796.1305X8  | A    | steel         | bright (black)      | 10.9  | M5 | 8  | 9,5  | 2,75 | 3   |
| K1796.1305X10 | A    | steel         | bright (black)      | 10.9  | M5 | 10 | 9,5  | 2,75 | 3   |
| K1796.1305X12 | A    | steel         | bright (black)      | 10.9  | M5 | 12 | 9,5  | 2,75 | 3   |
| K1796.1305X16 | A    | steel         | bright (black)      | 10.9  | M5 | 16 | 9,5  | 2,75 | 3   |
| K1796.1305X20 | A    | steel         | bright (black)      | 10.9  | M5 | 20 | 9,5  | 2,75 | 3   |
| K1796.1305X25 | A    | steel         | bright (black)      | 10.9  | M5 | 25 | 9,5  | 2,75 | 3   |
| K1796.1305X30 | A    | steel         | bright (black)      | 10.9  | M5 | 30 | 9,5  | 2,75 | 3   |
| K1796.1305X35 | A    | steel         | bright (black)      | 10.9  | M5 | 35 | 9,5  | 2,75 | 3   |
| K1796.1305X40 | A    | steel         | bright (black)      | 10.9  | M5 | 40 | 9,5  | 2,75 | 3   |
| K1796.1306X8  | A    | steel         | bright (black)      | 10.9  | M6 | 8  | 10,5 | 3,3  | 4   |
| K1796.1306X10 | A    | steel         | bright (black)      | 10.9  | M6 | 10 | 10,5 | 3,3  | 4   |
| K1796.1306X12 | A    | steel         | bright (black)      | 10.9  | M6 | 12 | 10,5 | 3,3  | 4   |
| K1796.1306X16 | A    | steel         | bright (black)      | 10.9  | M6 | 16 | 10,5 | 3,3  | 4   |
| K1796.1306X20 | A    | steel         | bright (black)      | 10.9  | M6 | 20 | 10,5 | 3,3  | 4   |
| K1796.1306X25 | A    | steel         | bright (black)      | 10.9  | M6 | 25 | 10,5 | 3,3  | 4   |
| K1796.1306X30 | A    | steel         | bright (black)      | 10.9  | M6 | 30 | 10,5 | 3,3  | 4   |