

Hex cap nut, high style DIN 1587 steel or stainless steel

Item description/product images



Description

Material:

Steel, stainless steel A2 or stainless steel A4.

Version:

Steel grade 6, bright or electro zinc-plated

Stainless steel A2-70, bright

Stainless steel A4-70, bright


Note:

Cap nuts are mainly used for decorative screw connections. The cap nut covers and protects the thread end. They are also used to protect against sharp edges on machines, equipment, fitness equipment and wherever people or objects could be injured or damaged by an exposed thread end.

Technical data:

From size D = M12 the cap nuts have a DIN 76-1 Form D thread undercut.

Drawings

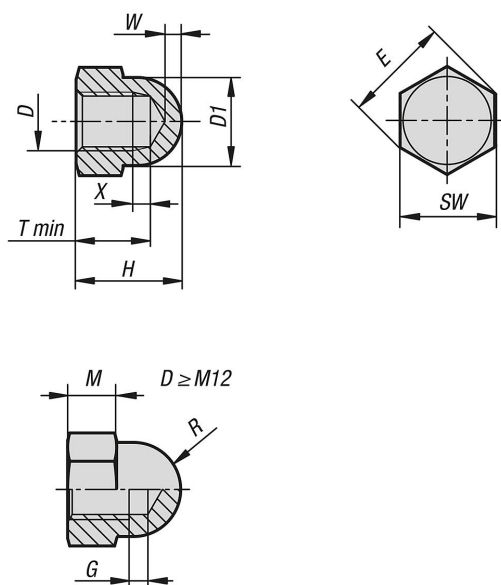

Overview of items

Hex cap nut, high style DIN 1587 steel or stainless steel

Order No.	Main material	Surface finish body	D	D1	T min.	H	M	SW	E	R	W	X	G
K1800.104	steel	bright	M4	6,5	5,26	8	3,2	7	7,66	3,25	2	1,4	-
K1800.105	steel	bright	M5	7,5	7,21	10	4	8	8,79	3,75	2	1,6	-
K1800.106	steel	bright	M6	9,5	7,71	12	5	10	11,05	4,75	2	2	-
K1800.108	steel	bright	M8	12,5	10,65	15	6,5	13	14,38	6,25	2	2,4	-
K1800.110	steel	bright	M10	15	12,65	18	8	17	18,9	7,5	2	3	-
K1800.112	steel	bright	M12	17	15,65	22	10	19	21,1	8,5	3	-	6,4
K1800.114	steel	bright	M14	20	17,65	25	11	22	23,9	10	4	-	7,3
K1800.116	steel	bright	M16	23	20,58	28	13	24	26,76	11,5	4	-	7,3
K1800.120	steel	bright	M20	28	25,58	34	16	30	32,95	14	5	-	9,3