
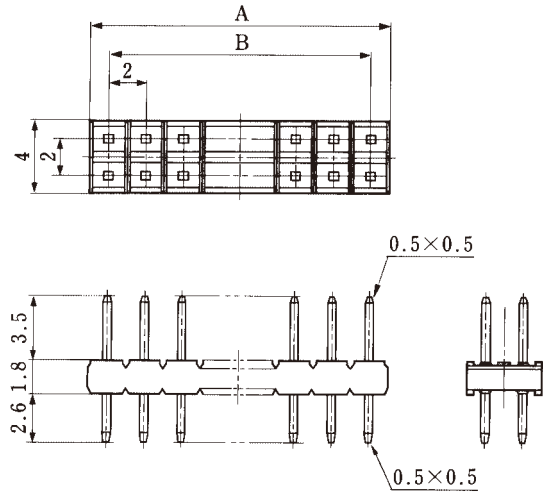


## ■ピンヘッダー


 
### ●A3Bストレートタイプ

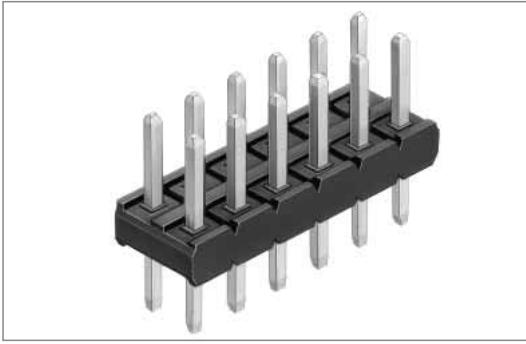



製品番号	HRS No.	極数	A	B	RoHS
A3B- 4PA-2DSA (51)	621-0401-1 51	4	4.0	2.0	○
A3B- 6PA-2DSA (51)	621-0402-4 51	6	6.0	4.0	
A3B- 8PA-2DSA (51)	621-0403-7 51	8	8.0	6.0	
A3B-10PA-2DSA (51)	621-0404-0 51	10	10.0	8.0	
A3B-12PA-2DSA (51)	621-0405-2 51	12	12.0	10.0	
A3B-14PA-2DSA (51)	621-0406-5 51	14	14.0	12.0	
A3B-16PA-2DSA (51)	621-0407-8 51	16	16.0	14.0	
A3B-18PA-2DSA (51)	621-0408-0 51	18	18.0	16.0	
A3B-20PA-2DSA (51)	621-0409-3 51	20	20.0	18.0	
A3B-22PA-2DSA (51)	621-0410-2 51	22	22.0	20.0	
A3B-24PA-2DSA (51)	621-0411-5 51	24	24.0	22.0	
A3B-26PA-2DSA (51)	621-0412-8 51	26	26.0	24.0	
A3B-28PA-2DSA (51)	621-0413-0 51	28	28.0	26.0	
A3B-30PA-2DSA (51)	621-0414-3 51	30	30.0	28.0	
A3B-32PA-2DSA (51)	621-0415-6 51	32	32.0	30.0	

(注) ご注文は100個単位でお願いします。

### ◆推奨基板寸法図

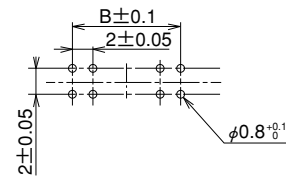


### ●A3Bライトアングルタイプ

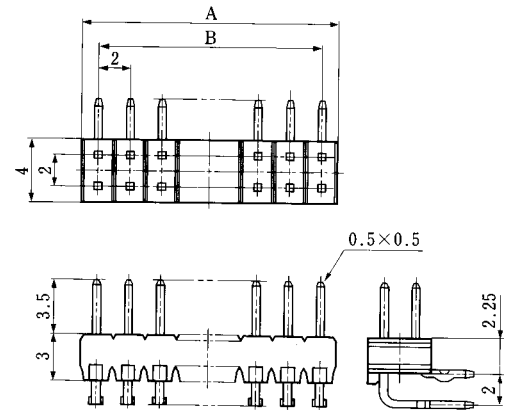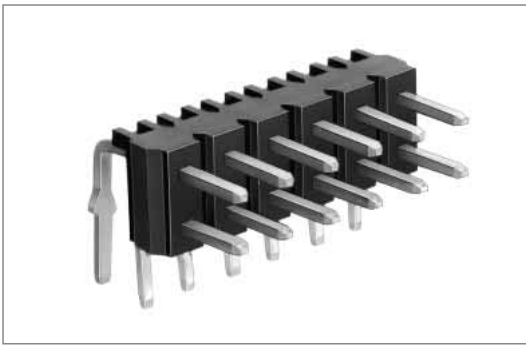

製品番号	HRS No.	極数	A	B	キンク位置(注1)	RoHS
A3B- 4PA-2DS (51)	621-0351-5 51	4	4.0	2.0	2本	○
A3B- 6PA-2DS (51)	621-0352-8 51	6	6.0	4.0	1端子おき1本又は2本	
A3B- 8PA-2DS (51)	621-0353-0 51	8	8.0	6.0	1端子おき2本	
A3B-10PA-2DS (51)	621-0354-3 51	10	10.0	8.0	1端子おき2本又は3本	
A3B-12PA-2DS (51)	621-0355-6 51	12	12.0	10.0	1端子おき3本	
A3B-14PA-2DS (51)	621-0356-9 51	14	14.0	12.0	1端子おき3本又は4本	
A3B-16PA-2DS (51)	621-0357-1 51	16	16.0	14.0	1端子おき4本	
A3B-18PA-2DS (51)	621-0358-4 51	18	18.0	16.0	1端子おき4本又は5本	
A3B-20PA-2DS (51)	621-0359-7 51	20	20.0	18.0	1端子おき5本	
A3B-22PA-2DS (51)	621-0360-6 51	22	22.0	20.0	1端子おき5本又は6本	
A3B-24PA-2DS (51)	621-0361-9 51	24	24.0	22.0	1端子おき6本	
A3B-26PA-2DS (51)	621-0362-1 51	26	26.0	24.0	1端子おき6本又は7本	
A3B-28PA-2DS (51)	621-0363-4 51	28	28.0	26.0	1端子おき7本	
A3B-30PA-2DS (51)	621-0364-7 51	30	30.0	28.0	1端子おき7本又は8本	
A3B-32PA-2DS (51)	621-0365-0 51	32	32.0	30.0	1端子おき8本	
A3B-44PA-2DS (51)	621-0377-9 51	44	44.0	42.0	1端子おき11本	
A3B-50PA-2DS (51)	621-0383-1 51	50	50.0	48.0	1端子おき12本又は13本	

(注1) ご注文は100個単位でお願いします。

(注2) 28極以上はφ0.95±0.04となります。

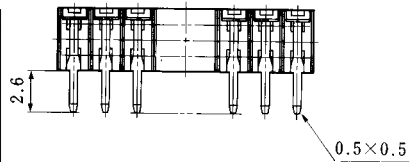

### ◆推奨基板寸法図(t=1.6)

