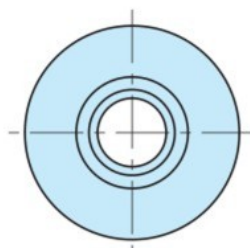
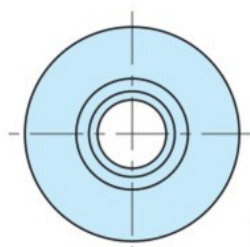


SD-C

スチール製 スイッチ ドッグ(円錐型)



IMAO

標準在庫品 RoHS

SD-C-SR
(精度穴)SD-C-ST
(メネジ)SD-C-SR
(精度穴)SD-C-ST
(メネジ)

六角穴付き止めネジ M1

黄銅ボール

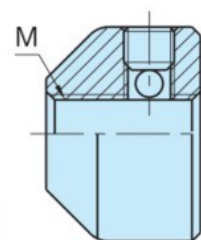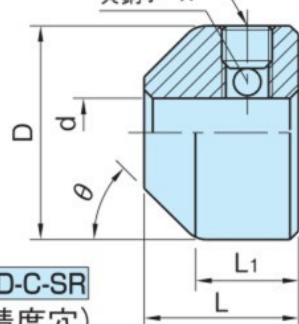

本体

S45C

四三酸化鉄皮膜

品番	シャフト 取付穴	D	d (H8)	M	L	L ₁	θ	M ₁	黄銅 ボール	質量 (g)	価 格	
SD25C30SR 8	精度穴	25	8	—	22	12	30°	M5×0.8 -5L	φ3.2	60	910	
SD25C30SR10			10	—						55	910	
SD25C30ST 8	メネジ		—	M 8×1.25						60	910	
SD25C30ST10			—	M10×1.5						55	910	
SD40C30SR12	精度穴	40	12	—	33	16			M8×1.25-8L	φ6.4	225	1,260
SD40C30SR16			16	—							205	1,260
SD40C30ST12	メネジ		—	M12×1.75							230	1,260
SD40C30ST16			—	M16×2							210	1,260
SD25C45SR 8	精度穴	25	8	—	18	12	45°		M5×0.8 -5L	φ3.2	60	750
SD25C45SR10			10	—								750
SD25C45ST 8	メネジ		—	M 8×1.25								750
SD25C45ST10			—	M10×1.5								750
SD40C45SR12	精度穴	40	12	—	26	16			M8×1.25-8L	φ6.4	225	930
SD40C45SR16			16	—							210	930
SD40C45ST12	メネジ		—	M12×1.75							225	930
SD40C45ST16			—	M16×2							210	930

使用例・使用方法

