
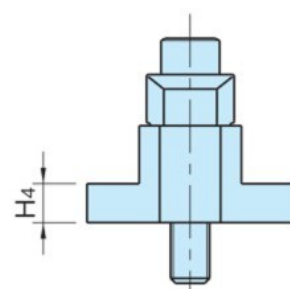
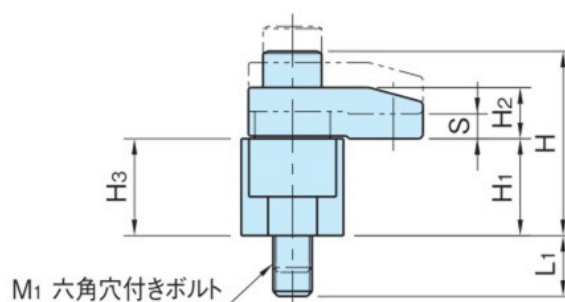


BJ130-B1

フッククランプセット(フランジタイプ)

標準在庫品 

IMAO

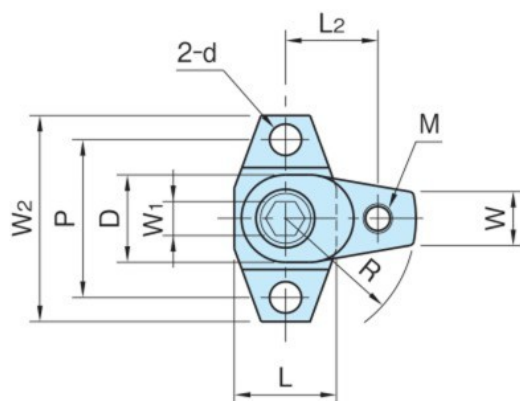

フック	ホルダー
SCM435 焼入焼戻 四三酸化鉄皮膜 研磨仕上	S45C 四三酸化鉄皮膜

品番	H ₁	S (クランプ ストローク)	M	L ₂	R	W ₂	L	M ₁	L ₁ (max.)	d	H ₄	P
BJ130-08020B1	25	10	—	—	20	50	24	M 8×1.25-50L	19	6.6	10	38
BJ130-08025B1					25							
BJ130-08030B1					30							
BJ130-10030B1	30	12	—	—	30	60	28	M10×1.5 -65L	21	9	12	45
BJ130-10040B1					40							

品番	H	H ₃	D	W	H ₂	W ₁	クランプ力 (kN)	許容締付トルク (N・m)	質量 (g)	価格
BJ130-08020B1	39	25	22	10	12	6	15	38	175	6,600
BJ130-08025B1							12	33	185	6,700
BJ130-08030B1							10	30	190	6,800
BJ130-10030B1	54	30	25	12	15	8	13	38	315	8,300
BJ130-10040B1							10	32	330	9,000