



MHS,MCT,MFSC アングルグリッパー

標準 在庫品 **RoHS****Fairlane**★One Point
MCT,MFSC:
超硬チップタイプ

MHS-127-4

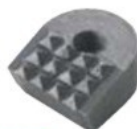

MHS-127-12

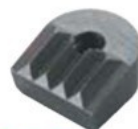

MHS-130-4



MCT-127-4



MCT-127-12



MCT-130-4



MFSC-127-4




MFSC-127-10




MFSC-130-4


タイプ	本体	チップ
MHS	SKH51 焼入焼戻 四三酸化鉄皮膜 HRC62	
MCT	SKH51 焼入焼戻 四三酸化鉄皮膜 HRC62	超硬 HRC72
MFSC		超硬 HRC72

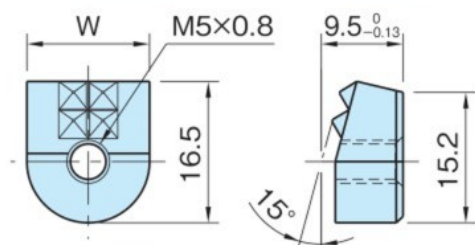


MHS-127-4,-127-4-10

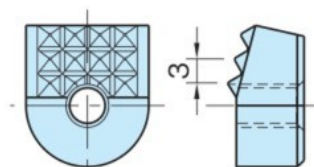


MHS-127-12

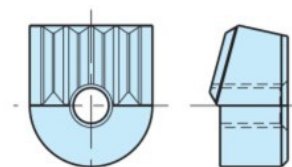


MHS-130-4

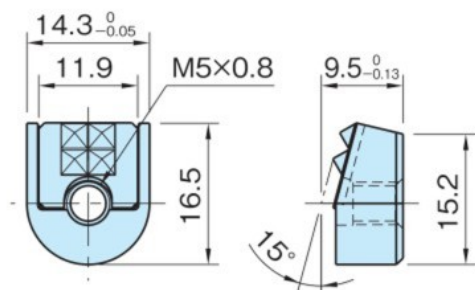


MCT-127-4

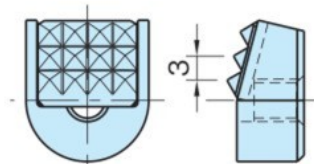


MCT-127-12

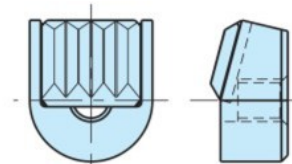


MCT-130-4

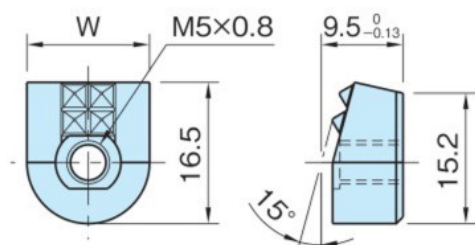

MFSC-127-4,-127-4-10

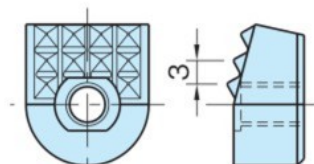

MFSC-127-10

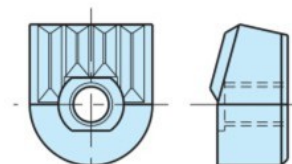

MFSC-130-4

MHS

品番	W (± 0.05)	質量 (g)	価格
MHS-127- 4-10	10	7	4,000
MHS-127- 4	14.3	11	2,800
MHS-127-12		12	2,800
MHS-130- 4			3,000

MCT

品番	質量 (g)	価格
MCT-127- 4	12	2,500
MCT-127-12	13	2,500
MCT-130- 4		2,500

MFSC

品番	W (± 0.05)	質量 (g)	価格
MFSC-127- 4-10	10	13	6,000
MFSC-127- 4	14.3		4,900
MFSC-127-10		20	4,900
MFSC-130- 4			5,400