


BJ761-N, BJ761-A


ヒンジ ボルト

標準在庫品 

IMAO

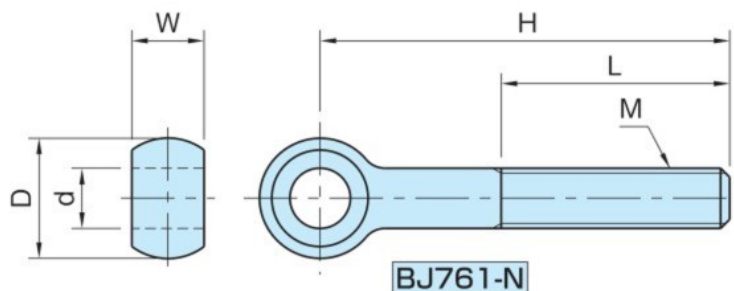

BJ761-N

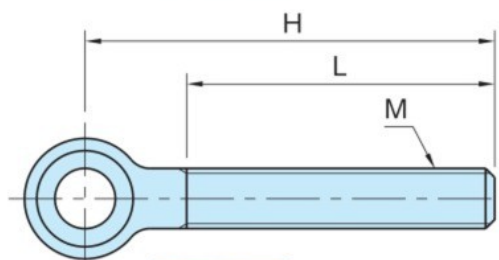

BJ761-A

本体

S45C
焼入焼戻
四三酸化鉄皮膜

BJ761-N BJ761-A

標準タイプ				全ネジタイプ				M	d (+0.2)	H	W (-0.2)	D
品番	L	質量(g)	価格	品番	L	質量(g)	価格					
BJ761-06001N	20	13	890	—	—	—	—	M 6×1	6	35 50	7	14
BJ761-06002N	25	16	950	BJ761-06002A	40	16	1,160					
BJ761-08011N	20	25	990	—	—	—	—	M 8×1.25	8	35	9	18
BJ761-08001N	30	30	990	BJ761-08001A	37	30	1,160			50		
BJ761-08002N		40	990	BJ761-08002A	62	40	1,280			75		
BJ761-10011N	45	45	1,110	—	—	—	—	M10×1.5	10	50	12	20
BJ761-10001N		60	1,110	BJ761-10001A	60	60	1,390			75		
BJ761-10002N		80	1,110	BJ761-10002A	85	80	1,510			100		
BJ761-12011N	30	73	1,280	—	—	—	—	M12×1.75	12	50	14	25
BJ761-12001N	50	95	1,280	BJ761-12001A	57	95	1,620			75		
BJ761-12002N		120	1,620	—	—	—	—			100		
BJ761-12003N		125	1,740	BJ761-12003A	107	125	1,850			125		
BJ761-16011N	60	210	1,850	BJ761-16011A	80	210	2,400	M16×2	16	100	17	32
BJ761-16001N		250	1,850	—	—	—	—			125		
BJ761-16002N		300	1,850	BJ761-16002A	130	300	2,700			150		
BJ761-20011N	55	340	2,700	BJ761-20011A	75	340	3,300	M20×2.5	18	100	22	40
BJ761-20001N	65	400	2,700	—	—	—	—			125		
BJ761-20002N		485	2,900	BJ761-20002A	125	485	3,500			150		

使用例・使用方法

