


Lタイプ

IQコード 030702

単位：mm

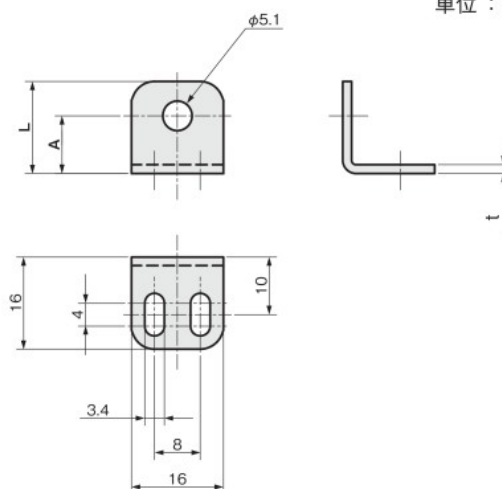

材質／表面処理

ステンレス SUS304

鉄 SPCC／カチオン電着塗装：黒

M5用 SUS304 板厚：t 1.5、SPCC 板厚：t 2.0

A	L	重量 (g)	品番	価格(円)	
			□：材質記号 SUS S 、SPCC Z	SUS304	SPCC
10	16	6	FS05LT010-□	290	260
12.5	18.5	7	FS05LT012-S	290	—
15	21	7	FS05LT015-□	290	280
17.5	23.5	8	FS05LT017-S	290	—
20	26	9	FS05LT020-□	290	280
22.5	28.5	9	FS05LT022-S	290	—
25	31	10	FS05LT025-S	290	—
27.5	33.5	11	FS05LT027-S	310	—
30	36	11	FS05LT030-S	310	—
32.5	38.5	12	FS05LT032-S	310	—
35	41	12	FS05LT035-S	310	—
37.5	43.5	13	FS05LT037-S	310	—
40	46	13	FS05LT040-S	310	—

M8用 SUS304 板厚：t 2.0、SPCC 板厚：t 2.3

単位：mm

A	L	重量 (g)	品番	価格(円)	
			□：材質記号 SUS S 、SPCC Z	SUS304	SPCC
15	24	13	FS08LT015-□	340	340
17.5	26.5	14	FS08LT017-S	340	—
20	29	15	FS08LT020-□	340	340
22.5	31.5	16	FS08LT022-S	340	—
25	34	17	FS08LT025-□	340	340
27.5	36.5	18	FS08LT027-S	350	—
30	39	19	FS08LT030-□	350	350
32.5	41.5	20	FS08LT032-S	350	—
35	44	21	FS08LT035-□	350	350
37.5	46.5	22	FS08LT037-S	360	—
40	49	23	FS08LT040-S	360	—
45	54	25	FS08LT045-S	360	—
50	59	26	FS08LT050-S	370	—
60	69	31	FS08LT060-S	400	—

