



410A

●ご注文No.表記例

410A 15

TYPE 歯数

スプロケットNo.

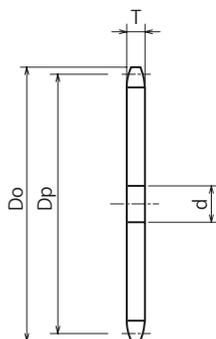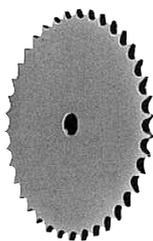

- チェーン……………No.410
- チェーンピッチ……………(P) 12.70mm
- ローリンク内幅……………(W) 3.40mm
- ローラ外径……………(Dr) 7.75mm
- 歯幅……………(T) 2.8 mm

 普通鋼

TYPE	歯数	外径 Do	ピッチ径 Dp	軸穴径 d		重量 kg	¥	Semi-F ¥
				下穴	最小			
410A	8	39	33.19	8	9	0.01	250	シリーズ追加検討中
	9	43	37.13	8	9	0.02	250	
	10	47	41.10	9	10	0.05	230	
	11	51	45.08	10	11	0.09	250	
	12	55	49.07	10	11	0.10	270	
	13	59	53.07	12	13	0.12	270	
	14	63	57.07	12	13	0.14	300	
	15	67	61.08	12	13	0.16	310	
	16	71	65.10	13	14	0.18	330	
	17	76	69.12	13	14	0.20	370	
	18	80	73.14	13	14	0.23	390	
	19	84	77.16	13	14	0.26	490	
	20	88	81.18	14	15	0.29	470	
	21	92	85.21	14	15	0.30	520	
	22	96	89.24	14	15	0.35	560	
	23	100	93.27	14	15	0.38	570	
	24	104	97.30	14	15	0.40	580	
	25	108	101.33	14	15	0.45	630	
	26	112	105.36	14	15	0.49	670	
	27	116	109.40	14	15	0.50	710	
	28	120	113.43	14	15	0.56	750	
	29	124	117.46	14	15	0.60	910	
	30	128	121.50	14	15	0.63	890	
	31	133	125.53	14	15	0.65	1,020	
	32	137	129.57	14	15	0.70	960	
	33	141	133.61	14	15	0.75	1,200	
	34	145	137.64	14	15	0.80	1,120	
	35	149	141.68	14	15	0.85	1,200	
	36	153	145.72	16	17	0.90	1,280	
	37	157	149.75	16	17	0.99	1,500	