


FBK60B

●ご注文No.表記例

FBK 60B 20 D25

TYPE 歯数 φD H7

スプロケットNo.

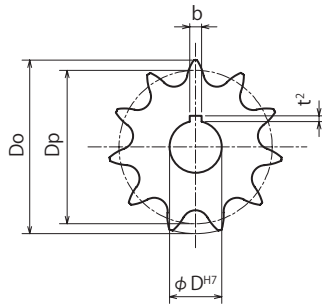

- チェーンNo.60
- チェーンピッチ(P)19.05mm
- ローリング内幅(W)12.70mm
- ローラ外径(Dr)11.91 mm
- 歯幅(T)11.7 mm

TYPE	歯数	外径Do	ピッチ径Dp	ボス径BD	ボス長さBL	a	重量kg	φD ^{H7}	¥
FBK 60B	10	68	61.65	★49	32	6	0.49	25	1,930
	11	76	67.62	★51	32	6	0.60	25 28 30	1,930
	12	83	73.60	51	32	8	0.69	24 25 28 30	1,930
	13	89	79.60	57	32	8	0.81	25 28 30	2,030
	14	95	85.61	62	32	8	0.96	20 25 28 30	2,080
	15	101	91.62	68	32	8	1.10	18 24 25 28 30	2,240
	16	107	97.65	73	32	8	1.30	24 25 28 30	2,340
	17	113	103.67	73	32	8	1.40	25 28 30	2,450
	18	119	109.71	83	40	12	2.00	25 28 30	2,810
	19	126	115.74	83	40	12	2.10	25 28 30 32 35 38	2,920
	20	132	121.78	83	40	12	2.20	25 28 30 32 35 38 40	3,020
	21	138	127.82	83	40	12	2.30	25 28 30	3,120
	22	144	133.86	83	40	12	2.50	28 30 35 40	3,380
	23	150	139.90	83	40	12	2.50	28 30	3,380
	24	156	145.95	83	40	12	2.60	25 30 35 38 40	3,540
	25	162	151.99	83	40	12	2.70	28 30 35 40	3,640
	26	168	158.04	83	40	12	2.90	30 35	3,750
	27	174	164.09	83	40	12	3.00	30 35 40	4,120
	28	180	170.14	83	40	12	3.10	30 35 40	4,060
	30	193	182.25	83	40	12	3.40	35 40	4,320