
 


NK35B

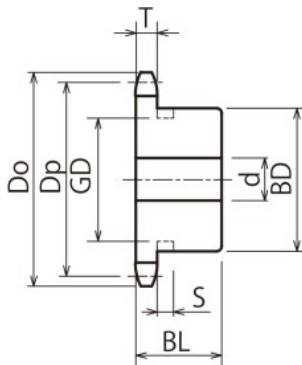

●ご注文表記例

NK35B 24



- チェーンNo.35
- チェーンピッチ(P)9.525mm
- ブッシュリンク内幅(W)4.78 mm
- ブッシュ外径(Dr)5.08 mm
- 歯幅(T)4.3 mm

※□はP215 K35Bと共通仕様です。

TYPE	歯数	外径 Do	ピッチ径 Dp	軸穴径 d			ボス径 BD	ボス長さ BL	形状	歯部	重量 kg	定価 (円)	Semi-F 定価(円)
				下穴	最小	最大							
NK 35B	8	29	24.89	8	9	10	★18.5	20	削出仕様	h m 歯先高周波焼入 機械構造用炭素鋼	0.04	330	2,800
	9	32	27.85	8	9	11	★21.5	20			0.05	280	2,400
	10	35	30.82	8	9	12	★24.5	20			0.08	280	2,400
	11	38	33.81	8	9	14	★27	20			0.09	310	2,400
	12	41	36.80	9	10	16	★30.5	20			0.12	340	2,600
	13	44	39.80	9	10	18	★32	20			0.12	330	2,500
	14	47	42.81	9	10	18	32	20			0.12	360	2,600
	15	51	45.81	9	10	20	35	20			0.16	400	2,600
	16	54	48.82	9	10	20	37	20			0.19	440	2,700
	17	57	51.84	11	12	25	41	20			0.22	440	2,700
	18	60	54.85	11	12	25	44	20			0.25	530	3,000
	19	63	57.87	11	12	28	47	20			0.28	570	3,100
	20	66	60.89	11	12	30	50	20			0.32	550	2,800
	21	69	63.91	11	12	32	53	20			0.36	560	2,800
	22	72	66.93	11	12	35	56	20			0.37	630	3,100
	23	75	69.95	11	12	38	60	20			0.38	690	3,200
	24	78	72.97	11	12	32	53	22			0.43	670	3,100
	25	81	76.00	11	12	32	53	22			0.44	710	3,100
	26	84	79.02	11	12	32	53	22			0.45	730	3,200
	27	87	82.05	11	12	32	53	22			0.46	830	3,300
28	90	85.07	11	12	32	53	22	0.48	830	3,300			
29	93	88.10	11	12	32	53	22	0.49	1,020	3,900			
30	96	91.12	11	12	32	53	22	0.51	830	3,300			
31	99	94.15	11	12	32	53	22	0.53	1,120	4,000			
32	102	97.18	11	12	32	53	22	0.54	890	3,200			
33	105	100.20	11	12	32	53	22	0.56	1,260	4,200			
34	109	103.23	11	12	32	53	22	0.57	960	3,300			
35	112	106.26	11	12	32	53	22	0.59	940	3,200			
36	115	109.29	12	13	32	53	22	0.61	1,020	3,500			
37	118	112.31	12	13	42	63	25	0.80	1,830	5,000			
38	121	115.34	12	13	42	63	25	0.82	1,180	3,700			
39	124	118.37	12	13	42	63	25	0.84	1,940	5,100			
40	127	121.40	12	13	42	63	25	0.85	1,260	3,800			