


鑄鉄製ひしフランジ形ユニット

UCFL形

円筒穴形，止ねじ式

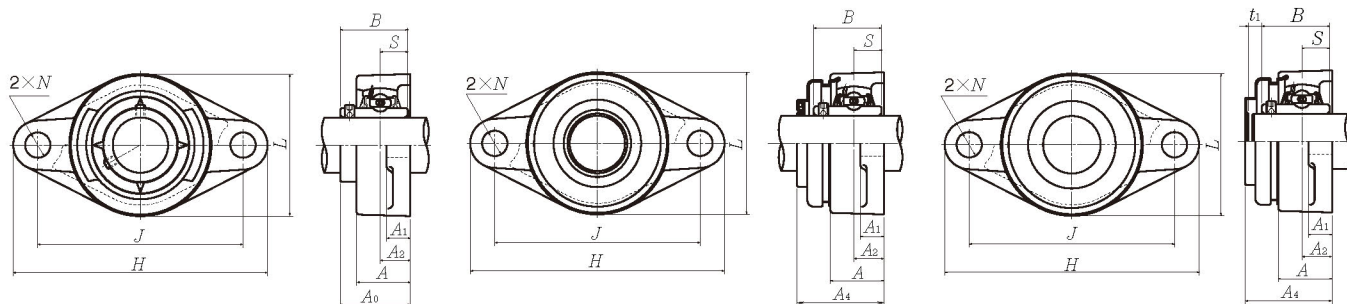

ゴムシール付鋼板製カバー付き

鋼板製閉じカバー付き

軸径 12～60mm

軸径 mm	ユニット① の呼び番号	寸 法 mm										取付け ボルト の呼び	軸 呼び番号	受	
		H	J	A ₂	A ₁	A	N	L	A ₀	B	S			基本動 定格荷重 C _r	基本静 定格荷重 C _{0r}
12	UCFL201	113	90	15	11	25.5	12	60	33.3	31	12.7	M10	UC201D1	12.8	6.65
15	UCFL202	113	90	15	11	25.5	12	60	33.3	31	12.7	M10	UC202D1	12.8	6.65
17	UCFL203	113	90	15	11	25.5	12	60	33.3	31	12.7	M10	UC203D1	12.8	6.65
20	UCFL204	113	90	15	11	25.5	12	60	33.3	31	12.7	M10	UC204D1	12.8	6.65
25	UCFL205	130	99	16	13	27	16	68	35.8	34.1	14.3	M14	UC205D1	14.0	7.85
	UCFLX05	141	117	18	13	30	12	83	40.2	38.1	15.9	M10	UCX05D1	19.5	11.3
	UCFL305	150	113	16	13	29	19	80	39	38	15	M16	UC305D1	21.2	10.9
30	UCFL206	148	117	18	13	31	16	80	40.2	38.1	15.9	M14	UC206D1	19.5	11.3
	UCFLX06	156	130	19	15	34	16	95	44.4	42.9	17.5	M14	UCX06D1	25.7	15.3
	UCFL306	180	134	18	15	32	23	90	44	43	17	M20	UC306D1	26.7	15.0
35	UCFL207	161	130	19	15	34	16	90	44.4	42.9	17.5	M14	UC207D1	25.7	15.3
	UCFLX07	171	144	21	16	38	16	105	51.2	49.2	19	M14	UCX07D1	29.1	17.8
	UCFL307	185	141	20	16	36	23	100	49	48	19	M20	UC307D1	33.5	19.1
40	UCFL208	175	144	21	15	36	16	100	51.2	49.2	19	M14	UC208D1	29.1	17.8
	UCFLX08	179	148	22	16	40	16	111	52.2	49.2	19	M14	UCX08D1	32.5	20.4
	UCFL308	200	158	23	17	40	23	112	56	52	19	M20	UC308D1	40.5	24.0
45	UCFL209	188	148	22	16	38	19	108	52.2	49.2	19	M16	UC209D1	32.5	20.4
	UCFLX09	189	157	23	16	40	16	116	55.6	51.6	19	M14	UCX09D1	35.0	23.2
	UCFL309	230	177	25	18	44	25	125	60	57	22	M22	UC309D1	53.0	32.0
50	UCFL210	197	157	22	16	40	19	115	54.6	51.6	19	M16	UC210D1	35.0	23.2
	UCFLX10	216	184	26	18	44	19	133	59.4	55.6	22.2	M16	UCX10D1	43.5	29.2
	UCFL310	240	187	28	19	48	25	140	67	61	22	M22	UC310D1	62.0	38.5
55	UCFL211	224	184	25	18	43	19	130	58.4	55.6	22.2	M16	UC211D1	43.5	29.2
	UCFL311	250	198	30	20	52	25	150	71	66	25	M22	UC311D1	71.5	45.0
60	UCFL212	250	202	29	18	48	23	140	68.7	65.1	25.4	M20	UC212D1	52.5	36.0
	UCFL312	270	212	33	22	56	31	160	78	71	26	M27	UC312D1	82.0	52.0

① 御要求により球状黒鉛鑄鉄製の軸受箱も製作している。
この場合は呼び番号の後に記号 "N1" が付く。例 UCFL210N1