


UCFC形

円筒穴形，止ねじ式

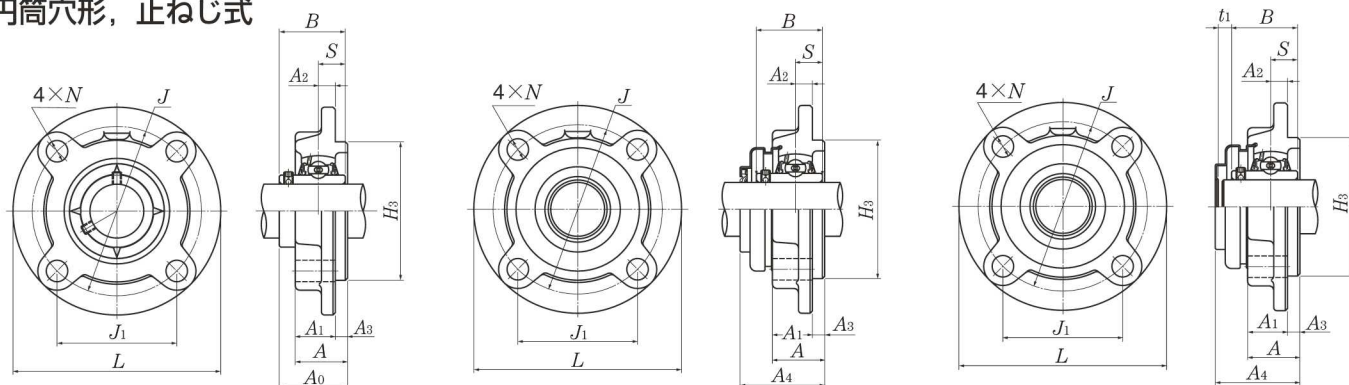

ゴムシール付鋼板製カバー付き

鋼板製閉じカバー付き

軸径 12～70mm

軸径 mm	ユニット① の呼び番号	寸 法														取付け ボルト の呼び	軸 呼び番号	軸 受	
		mm																基本動 定格荷重 C _r	基本静 定格荷重 C _{or}
		<i>L</i>	<i>J</i>	(<i>J</i> ₁)	<i>A</i> ₂	<i>N</i>	<i>A</i> ₃	標準及び鋼板 製カバー付軸 受箱の場合 <i>A</i> ₁	鋳鉄製カバ ー付軸受箱 の場合 <i>A</i> ₁	<i>A</i>	<i>H</i> ₃	<i>A</i> ₀	<i>B</i>	<i>S</i>					
12	UCFC201	100	78	55.2	10	12	5	20.5	20.5	25.5	62	33.3	31	12.7	M10	UC201D1	12.8	6.65	
15	UCFC202	100	78	55.2	10	12	5	20.5	20.5	25.5	62	33.3	31	12.7	M10	UC202D1	12.8	6.65	
17	UCFC203	100	78	55.2	10	12	5	20.5	20.5	25.5	62	33.3	31	12.7	M10	UC203D1	12.8	6.65	
20	UCFC204	100	78	55.2	10	12	5	20.5	20.5	25.5	62	33.3	31	12.7	M10	UC204D1	12.8	6.65	
25	UCFC205	115	90	63.6	10	12	6	21	22	27	70	35.8	34.1	14.3	M10	UC205D1	14.0	7.85	
	UCFCX05	111	92	65.1	10	9.5	6	24	—	30	76	38.2	38.1	15.9	M 8	UCX05D1	19.5	11.3	
30	UCFC206	125	100	70.7	10	12	8	23	24.5	31	80	40.2	38.1	15.9	M10	UC206D1	19.5	11.3	
	UCFCX06	127	105	74.2	8	12	9.5	22.5	—	32	85	42.9	42.9	17.5	M10	UCX06D1	25.7	15.3	
35	UCFC207	135	110	77.8	11	14	8	26	26	34	90	44.4	42.9	17.5	M12	UC207D1	25.7	15.3	
	UCFCX07	133	111	78.5	9	12	11	26	—	37	92	50.2	49.2	19	M10	UCX07D1	29.1	17.8	
40	UCFC208	145	120	84.9	11	14	10	26	27.5	36	100	51.2	49.2	19	M12	UC208D1	29.1	17.8	
	UCFCX08	133	111	78.5	9	12	11	26	—	37	92	50.2	49.2	19	M10	UCX08D1	32.5	20.4	
45	UCFC209	160	132	93.3	10	16	12	26	28	38	105	52.2	49.2	19	M14	UC209D1	32.5	20.4	
	UCFCX09	155	130	91.9	8	14	12	25	—	37	108	52.6	51.6	19	M12	UCX09D1	35.0	23.2	
50	UCFC210	165	138	97.6	10	16	12	28	29	40	110	54.6	51.6	19	M14	UC210D1	35.0	23.2	
	UCFCX10	162	136	96.2	7	14	16	25	—	41	118	56.4	55.6	22.2	M12	UCX10D1	43.5	29.2	
55	UCFC211	185	150	106.1	13	19	12	31	32.5	43	125	58.4	55.6	22.2	M16	UC211D1	43.5	29.2	
	UCFCX11	180	152	107.5	4	16	22	26	—	48	127	65.7	65.1	25.4	M14	UCX11D1	52.5	36.0	
60	UCFC212	195	160	113.1	17	19	12	36	38	48	135	68.7	65.1	25.4	M16	UC212D1	52.5	36.0	
	UCFCX12	194	165	116.7	11	16	20	33	—	53	140	70.7	65.1	25.4	M14	UCX12D1	57.5	40.0	
65	UCFC213	205	170	120.2	16	19	14	36	38	50	145	69.7	65.1	25.4	M16	UC213D1	57.5	40.0	
	UCFCX13	194	165	116.7	11	16	20	33	—	53	140	75.4	74.6	30.2	M14	UCX13D1	62.0	44.0	
70	UCFC214	215	177	125.2	17	19	14	40	39.5	54	150	75.4	74.6	30.2	M16	UC214D1	62.0	44.0	
	UCFCX14	222	190	134.4	14	19	20	36	—	56	164	78.5	77.8	33.3	M16	UCX14D1	66.0	49.5	

① 御要求により球状黒鉛鋳鉄製の軸受箱も製作している。
この場合は呼び番号の後に記号 "N1" が付く。例 UCFC210N1