


## Nuts for T-Slots · DIN 508 with antislipping device EH 23010.

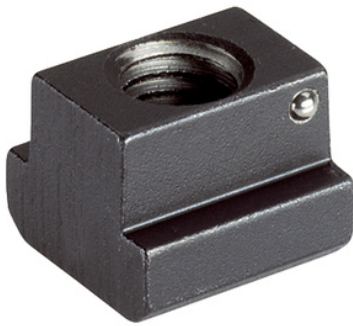

### Product Description

These nuts for T-slots (slot nuts) are manufactured according to DIN 508. The spring element avoids vertical and horizontal slipping of the nut.

### Material

#### Ball

- Ball-bearing steel, hardened


#### T-nut

- Heat-treated steel, tempered, quality 10, blackened

#### Spring

- stainless steel

### Drawing

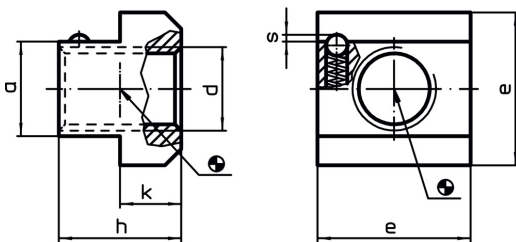

### Order information

T-slot size [mm]	d	a	Dimensions				Spring load		[g]	Art. No.
			e	h	k	s	F <sub>1</sub> ~	F <sub>2</sub> ~		
			[mm]				[N]			
10	M 8	9.6	15	12	6	0.65	3.25	4.75	12	<a href="#">23010.0811</a>
12	M10	11.6	18	14	7	0.80	4.70	12.60	20	<a href="#">23010.0813</a>
14	M12	13.6	22	16	8	0.90	8.50	14.20	34	<a href="#">23010.0815</a>
18	M16	17.6	28	20	10	1.00	7.80	13.50	68	<a href="#">23010.0819</a>
22	M20	21.6	35	28	14	1.60	5.00	12.80	147	<a href="#">23010.0823</a>