

T-Bolts • DIN 787

EH 23030.



Product Description

T-bolts when combined with DIN 6330 fixture nuts (EH 23070.) and DIN 6340 plain washers (EH 23060.) become complete clamping bolts. These T-bolts are characterised by the rolled thread.

Material

- Heat-treated steel, black, forged, T-slot guidance milled

More information

Notes

Special types on request.


References

For torques and strengths please refer to appendix - Technical Data -

Further products

- Shaft / Plain Washers, DIN 6340 heat-treated
- Fixture Nuts, DIN 6330 (height 1,5 d)

Drawing

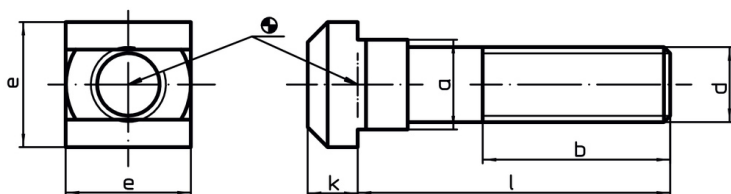

Order information

T-slot size	Dimensions							Art. No.
[mm]	d	l	a [mm]	b	e	k		
quality 10.9								
6	M 6	25	5.6	15	10	4	7.7 g	23030.0061
6	M 6	40	5.6	28	10	4	10.0 g	23030.0062
6	M 6	63	5.6	40	10	4	14.0 g	23030.0063
8	M 8	32	7.6	22	13	6	19.0 g	23030.0081
8	M 8	50	7.6	35	13	6	25.0 g	23030.0082
8	M 8	80	7.6	50	13	6	34.0 g	23030.0083
10	M10	40	9.6	30	15	6	33.0 g	23030.0101
10	M10	63	9.6	45	15	6	44.0 g	23030.0102
10	M10	100	9.6	60	15	6	61.0 g	23030.0103
12	M12	50	11.6	35	18	7	54.0 g	23030.0121
12	M12	63	11.6	40	18	7	66.0 g	23030.0125¹⁾
12	M12	80	11.6	55	18	7	79.0 g	23030.0122
12	M12	125	11.6	75	18	7	111.0 g	23030.0123
12	M12	160	11.6	100	18	7	136.0 g	23030.0126
12	M12	200	11.6	120	18	7	164.0 g	23030.0124
14	M12	50	13.6	35	22	8	76.0 g	23030.0141
14	M12	63	13.6	45	22	8	85.0 g	23030.0145¹⁾
14	M12	80	13.6	55	22	8	97.0 g	23030.0142
14	M12	125	13.6	75	22	8	129.0 g	23030.0143
14	M12	160	13.6	100	22	8	170.0 g	23030.0146
14	M12	200	13.6	120	22	8	182.0 g	23030.0144

¹⁾ DIN standards do not include these dimensions.