

Collar Nuts • DIN 6331 (height 1,5 d)

EH 23080.

Product Description

The collar nuts (flanged nuts) are manufactured according to DIN 6331.



Material


- Heat-treated steel, tempered, quality 10, phosphated
- Stainless steel 1.4305

More information

References

For torques and strengths please refer to appendix - Technical Data -

Drawing

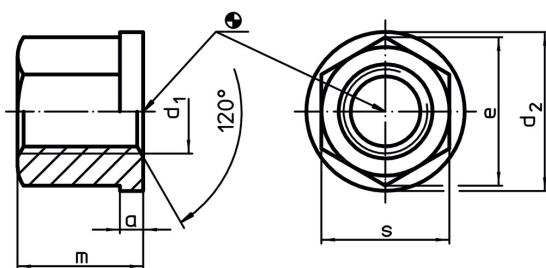

Order information

d ₁	a	Dimensions					Art. No.
		d ₂	e	m	s		
[mm]							[g]
Heat-treated steel							
M 6	3.0	14	11.5	9	10	5.4	23080.0006
M 8	3.5	18	15.0	12	13	12.0	23080.0008
M10	4.0	22	18.5	15	16	22.0	23080.0010
M12	4.0	25	20.8	18	18	30.0	23080.0012
M14	4.5	28	24.2	21	21	47.0	23080.0014¹⁾
M16	5.0	31	27.7	24	24	67.0	23080.0016
M18	5.5	34	31.2	27	27	97.0	23080.0018¹⁾
M20	6.0	37	34.6	30	30	129.0	23080.0020
M22	6.0	40	39.3	33	34	179.0	23080.0022¹⁾
M24	6.0	45	41.6	36	36	213.0	23080.0024
M30	8.0	58	53.1	45	46	468.0	23080.0030
M36	10.0	68	63.5	54	55	783.0	23080.0036
stainless steel							
M 8	3.5	18	15.0	12	13	12.0	23080.0108²⁾
M10	4.0	22	18.5	15	17	25.0	23080.0110²⁾
M12	4.0	25	20.8	18	19	36.0	23080.0112²⁾
M16	5.0	31	27.7	24	24	70.0	23080.0116²⁾
M20	6.0	37	34.6	30	30	130.0	23080.0120²⁾

¹⁾ DIN standards do not include these dimensions.

²⁾ DIN standard do not include these material.