

Eccentric Clamping Clamps

EH 23270.



Product Description

These clamps have a high clamping force for low clamping heights. The body from brass provides a gentle but safe clamping.

Material


Eccentric screw

- steel

Body

- Brass

Drawing

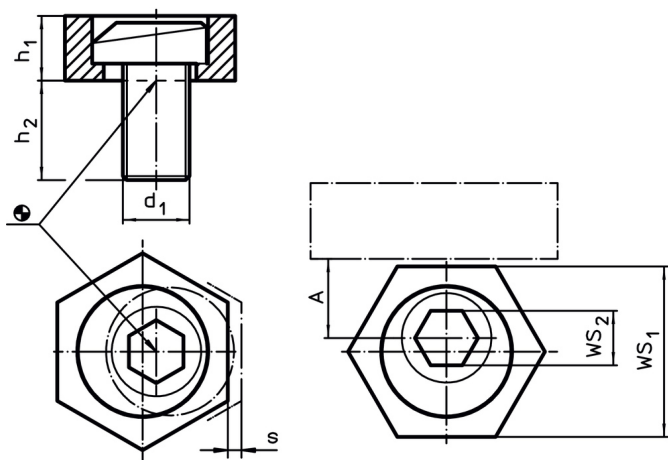

Order information

d ₁	Dimensions			A	WS ₁	WS ₂	Clamping force max.	Tightening torque max.		Art. No.
	h ₁	h ₂	s							
	[mm]			[mm]	[mm]	[mm]	[kN]	[Nm]	[g]	
M 4	2.8	9.6	0.75	3.8	7.93	3	0.9	2.5	3.5	23270.0104
M 6	4.8	11.2	1.00	7.8	15.86	4	3.4	10.0	11.0	23270.0106
M 8	4.8	15.0	1.00	10.2	20.60	5	3.6	18.0	20.0	23270.0108
M10	6.3	19.0	1.30	10.2	20.60	7	7.0	26.0	27.0	23270.0110
M12	9.5	22.8	2.00	12.7	25.40	8	9.0	75.0	54.0	23270.0112
M16	12.7	28.5	2.50	15.0	30.13	12	12.0	120.0	108.0	23270.0116