

Crank Handles • stainless steel precision casting

EH 24330.



Product Description

Flat side of the hub is machined.

Material

Axle part

- Stainless steel 1.4301


Handle body

- Stainless steel 1.4308

Cylindrical handle

- Thermosetting plastic PF 31, black

Drawing

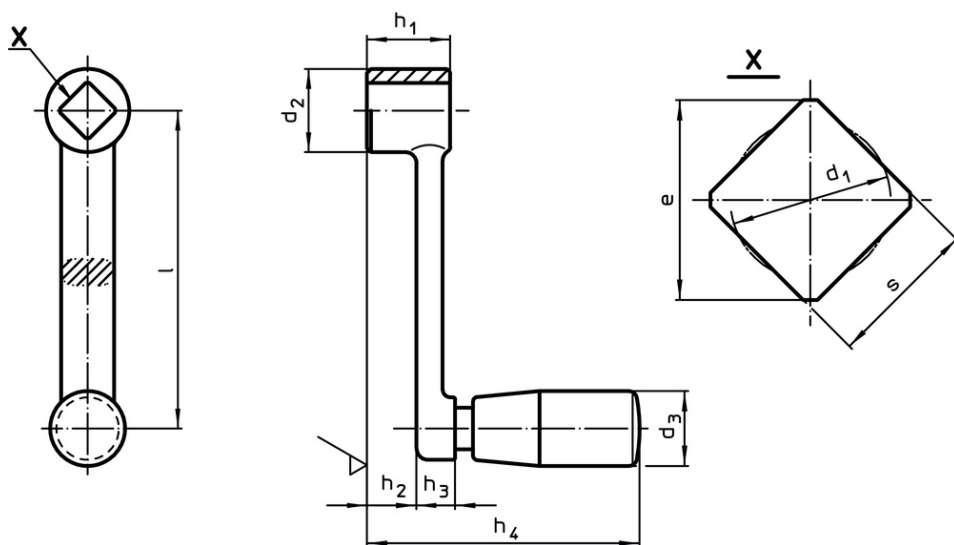

Order information

Dimensions									d ₃ Cylindrical handle Ø EH 24530.		Art. No.
l	s H11	e min.	d ₁ max.	d ₂	h ₁	h ₂ ~	h ₃	h ₄ ~	[mm]	[g]	
[mm]											
80	10	13.1	10.5	22	22	15.4	6.6	64.5	18	124	24330.0520
100	12	16.1	12.6	26	26	17.7	8.3	78.5	21	191	24330.0530
125	14	18.1	14.7	28	28	18.8	9.2	95.5	23	320	24330.0540
160	17	22.2	17.9	32	32	22.6	9.4	99.5	23	370	24330.0550