

Ball Knobs • metal types similar to DIN 319

EH 24561.

Product Description



Material


- Steel, polished, bright
- Stainless steel 1.4305, dull blasted
- Aluminium, polished

More information

Notes

Supplement DIN 319 Form C about metallic versions.

Drawing

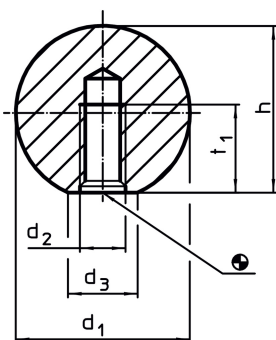

Order information

Dimensions						Art. No.
d ₁	d ₂	d ₃ ~	h ~	t ₁ min.		
[mm]						
steel						
16	M 4	8	15.0	7.0	16	24561.0016
20	M 5	12	18.0	9.0	26	24561.0020
25	M 6	15	22.5	11.0	58	24561.0025
32	M 8	18	29.0	14.5	116	24561.0032
40	M10	22	37.0	18.0	241	24561.0040
50	M12	27	46.0	21.0	475	24561.0050
stainless steel						
16	M 4	8	15.0	7.0	16	24561.0216
20	M 5	12	18.0	9.0	31	24561.0220
25	M 6	15	22.5	11.0	59	24561.0225
32	M 8	18	29.0	14.5	122	24561.0232
40	M10	22	37.0	18.0	242	24561.0240
Aluminium Al						
16	M 4	8	15.0	7.0	7	24561.0116
20	M 5	12	18.0	9.0	12	24561.0120
25	M 6	15	22.5	11.0	22	24561.0125
32	M 8	18	29.0	14.5	44	24561.0132
40	M10	22	37.0	18.0	87	24561.0140
50	M12	27	46.0	21.0	173	24561.0150