

Handwheels • DIN 950 light metal EH 24590.

Product Description

Hub machined; rim turned and mirror-finished on all sides, non-machined surfaces cleanly blasted.



Material

Handwheel

- Light metal Al

Machine handle DIN 39 EH 24450.

- Steel, turned, zinc-plated by galvanization, passivated

Machine handle DIN 98 EH 24460. rotating

- Steel, turned, zinc-plated by galvanization, passivated

Assembly


Shaft-end washers EH 22270. for axial fastening.

More information

Further products

- Shaft-End Washers
- Rotating Machine Handles, DIN 98

Drawing

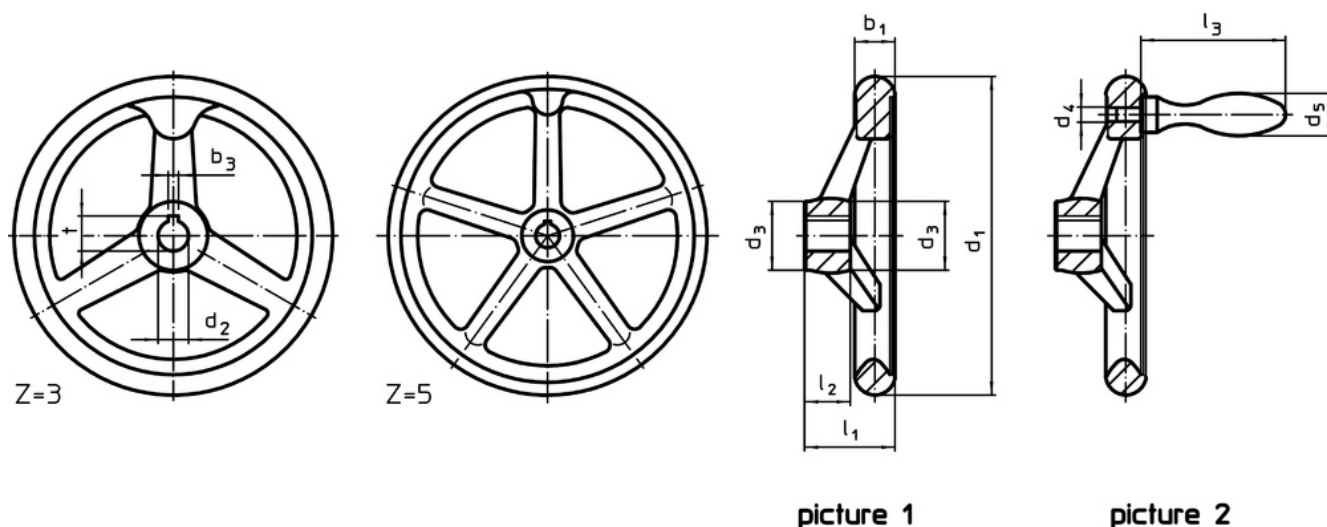

The orientation of the hub keyway may be different than shown in the drawing.

Order information

Dimensions								Hub keyway, DIN 6885 sheet 1		Number of spokes z	Corresponding machine handle DIN 39 / DIN 98		Art. No.	
d ₁	d ₂ H7	d ₃	d ₄	d ₅	l ₁ ~	l ₂	l ₃ ~	b ₃	t					
[mm]								[mm]						[mm]
without hub keyway, without handle, form B-F/A (formerly: A 4) – picture 1														
80	10	24	–	–	29	16	–	–	–	3	–	129 g	24590.0000	
80	12	24	–	–	29	16	–	–	–	3	–	128 g	24590.0001	
100	10	26	–	–	33	17	–	–	–	3	–	207 g	24590.0005	
100	12	26	–	–	33	17	–	–	–	3	–	205 g	24590.0006	
125	12	28	–	–	36	18	–	–	–	3	–	292 g	24590.0010	
125	14	28	–	–	36	18	–	–	–	3	–	298 g	24590.0011	
140	14	30	–	–	39	19	–	–	–	3	–	394 g	24590.0015	
140	16	30	–	–	39	19	–	–	–	3	–	363 g	24590.0016	
160	14	32	–	–	40	20	–	–	–	3	–	480 g	24590.0020	
160	16	32	–	–	40	20	–	–	–	3	–	471 g	24590.0021	
200	18	38	–	–	45	24	–	–	–	3	–	783 g	24590.0030	
200	22	38	–	–	45	24	–	–	–	3	–	770 g	24590.0031	
250	22	45	–	–	50	28	–	–	–	5	–	1509 g	24590.0040	
250	26	45	–	–	50	28	–	–	–	5	–	1510 g	24590.0041	