

Palm Grips • DIN 6335 stainless steel, die-cast EH 24631.

Product Description

These palm grips are manufactured according to DIN 6335.


Material

Handle

- Stainless steel A2, dull blasted



Drawing

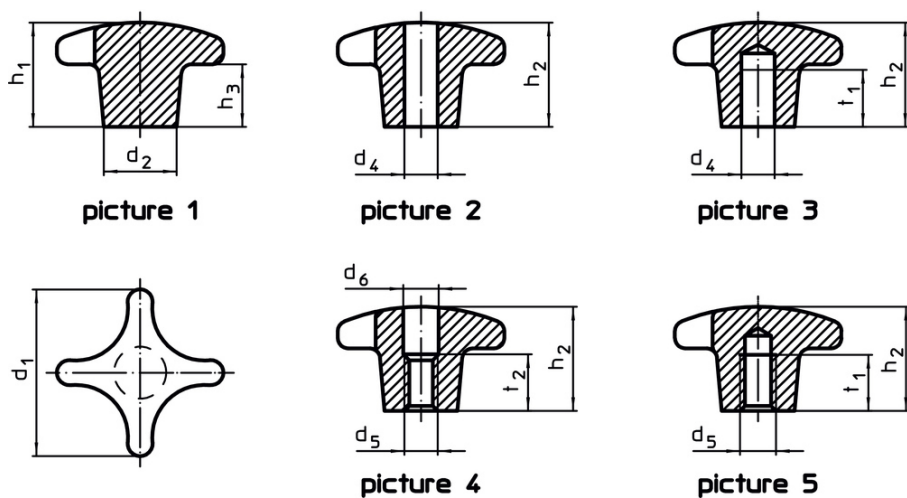

Order information

Dimensions											Art. No.
d ₁	d ₂	d ₅	d ₆	h ₁	h ₂	h ₃	t ₁ min.	t ₂			
[mm]										[g]	
raw part, form A – picture 1											
32	12	–	–	21	–	10	–	–	–	41	24631.0032
40	14	–	–	26	–	14	–	–	–	70	24631.0040
50	18	–	–	34	–	20	–	–	–	128	24631.0050
63	20	–	–	42	–	25	–	–	–	227	24631.0063
with thread, drilled out, form D – picture 4											
32	12	M 6	6.4	–	20	–	–	10	–	36	24631.0332
40	14	M 8	8.4	–	25	–	–	13	–	60	24631.0340
50	18	M10	10.5	–	32	–	–	16	–	100	24631.0350
63	20	M12	13.0	–	40	–	–	20	–	186	24631.0363
with threaded blind hole, form E – picture 5											
32	12	M 6	–	–	20	–	12	–	–	38	24631.0432
40	14	M 8	–	–	25	–	15	–	–	70	24631.0440
50	18	M10	–	–	32	–	18	–	–	114	24631.0450
63	20	M12	–	–	40	–	22	–	–	205	24631.0463