

Star Grips • stainless steel, solid
EH 24690.

Product Description

Version without dirt trap. Convenient for all applications having high hygienic requirements (e.g. food industry).




Material

Handle

- Stainless steel 1.4305, dull blasted

Drawing

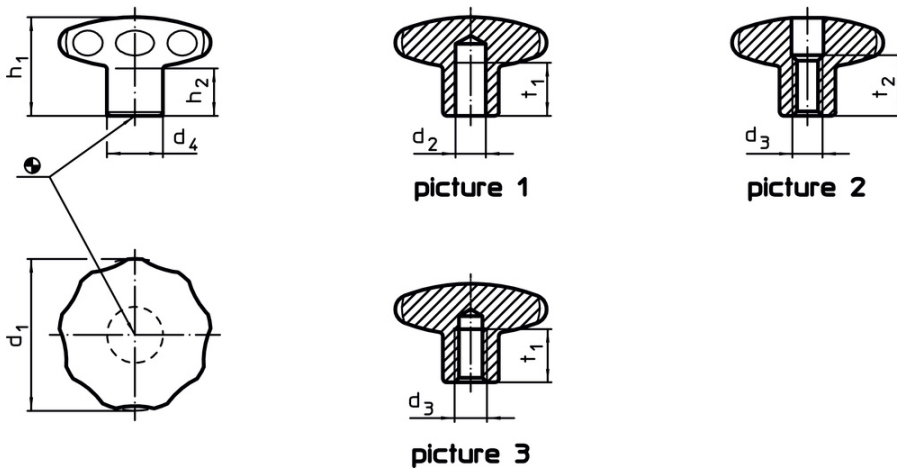

Order information

d ₁	d ₂ h ₇	d ₃	Dimensions					[g]	Art. No.
			d ₄	h ₁	h ₂	t ₁ min.	t ₂		
[mm]									
with smooth blind hole – picture 1									
40	8	–	18	30.5	15	12	–	131	24690.0643
50	10	–	21	34.0	17	15	–	223	24690.0653
60	12	–	25	39.0	18	18	–	388	24690.0663
with thread, drilled-out – picture 2									
40	–	M 8	18	30.5	15	–	13	140	24690.0644
50	–	M10	21	34.0	17	–	16	216	24690.0654
60	–	M12	25	39.0	18	–	20	362	24690.0664
with threaded blind hole – picture 3									
40	–	M 6	18	30.5	15	12	–	134	24690.0645
40	–	M 8	18	30.5	15	12	–	132	24690.0646
50	–	M 8	21	34.0	17	15	–	226	24690.0655
50	–	M10	21	34.0	17	15	–	270	24690.0656
60	–	M10	25	39.0	18	18	–	395	24690.0665
60	–	M12	25	39.0	18	18	–	384	24690.0666