

Star Grip Screws • DIN 6336 plastic EH 24740.



Product Description

Material

Handle

- DIN 7708 - thermosetting plastic (PF 31), black similar to RAL 9005

Screw


- Steel, zinc-plated by galvanization
- Stainless steel A2

More information

Notes

Special types, e.g. differing lengths or screws from brass / stainless steel on request.

Drawing

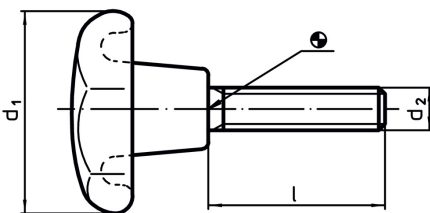

Order information

d ₁	Dimensions		l	max. [°C]	[g]	Art. No.
	d ₂ [mm]					
form L, steel						
25	M 5		10	110	7.3	24740.0051
25	M 5		15	110	7.4	24740.0053
25	M 5		20	110	8.7	24740.0056
25	M 5		25	110	8.7	24740.0058
25	M 5		30	110	9.2	24740.0059
32	M 6		15	110	14.0	24740.0101
32	M 6		20	110	15.0	24740.0104
32	M 6		25	110	14.0	24740.0106
32	M 6		30	110	16.0	24740.0107
32	M 6		40	110	17.0	24740.0110
40	M 8		20	110	28.0	24740.0152
40	M 8		25	110	31.0	24740.0154
40	M 8		30	110	32.0	24740.0155
40	M 8		40	110	35.0	24740.0158
40	M 8		50	110	38.0	24740.0160
50	M10		25	110	51.0	24740.0202
50	M10		30	110	54.0	24740.0203
50	M10		40	110	60.0	24740.0206
50	M10		50	110	64.0	24740.0208
50	M10		60	110	73.0	24740.0209
63	M12		30	110	101.0	24740.0251
63	M12		40	110	108.0	24740.0254
63	M12		50	110	115.0	24740.0256
63	M12		60	110	121.0	24740.0257
63	M12		80	110	143.0	24740.0260
80	M16		40	110	223.0	24740.0302
80	M16		50	110	237.0	24740.0304
80	M16		60	110	249.0	24740.0305
80	M16		80	110	274.0	24740.0308