


ピン・ボタン六角穴ボルト

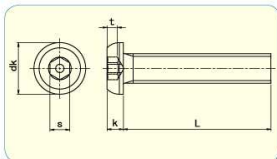

- 材質
ステンレス A2
ステンレス A2 黒染め
ステンレス A2 ナイロロック加工

■六角穴の中央にピンが立っていて通常の六角レンチが入りません。

■インチねじ在庫あります。



	M3	M4	M5	M6	M8	M10	M12
dk	5.7	7.6	9.5	10.5	14	17.5	21
s	1.65	2.2	2.75	3.3	4.4	5.5	6.6
k	2	2.5	3	4	5	6	8
ドライバーサイズ	2	2.5	3	4	5	6	8



メートルねじ

サイズ	製品コード			梱包	
	ステンレス A2	ステン黒染め	ナイロック加工		
M3	6	HE010306	HE010306BK	HE010306NY	100
	8	HE010308	HE010308BK	HE010308NY	100
	10	HE010310	HE010310BK	HE010310NY	100
	12	HE010312	HE010312BK	HE010312NY	100
	16	HE010316	HE010316BK	HE010316NY	100
	20	HE010320	HE010320BK	HE010320NY	100
M4	6	HE010406	HE010406BK	HE010406NY	100
	8	HE010408	HE010408BK	HE010408NY	100
	10	HE010410	HE010410BK	HE010410NY	100
	12	HE010412	HE010412BK	HE010412NY	100
	16	HE010416	HE010416BK	HE010416NY	100
	20	HE010420	HE010420BK	HE010420NY	100
M5	10	HE010510	HE010510BK	HE010510NY	100
	12	HE010512	HE010512BK	HE010512NY	100
	16	HE010516	HE010516BK	HE010516NY	100
	20	HE010520	HE010520BK	HE010520NY	100
	25	HE010525	HE010525BK	HE010525NY	100
	30	HE010530	HE010530BK	HE010530NY	100
M6	8	HE010608	HE010608BK	HE010608NY	100
	10	HE010610	HE010610BK	HE010610NY	100
	12	HE010612	HE010612BK	HE010612NY	100
	16	HE010616	HE010616BK	HE010616NY	100
	20	HE010620	HE010620BK	HE010620NY	100
	25	HE010625	HE010625BK	HE010625NY	100
M8	30	HE010630	HE010630BK	HE010630NY	100
	35	HE010635	HE010635BK	HE010635NY	100
	40	HE010640	HE010640BK	HE010640NY	100
	45	HE010645	HE010645BK	HE010645NY	100
	50	HE010650	HE010650BK	HE010650NY	100
	55	HE010655	HE010655BK	HE010655NY	100
	60	HE010660	HE010660BK	HE010660NY	100
	70	HE010670	HE010670BK	HE010670NY	100
	80	HE010680	HE010680BK	HE010680NY	100
	90	HE010690	HE010690BK	HE010690NY	100

サイズ	製品コード			梱包	
	ステンレス A2	ステン黒染め	ナイロック加工		
M8	10	HE010810	HE010810BK	HE010810NY	100
	12	HE010812	HE010812BK	HE010812NY	100
	16	HE010816	HE010816BK	HE010816NY	100
	20	HE010820	HE010820BK	HE010820NY	100
	25	HE010825	HE010825BK	HE010825NY	100
	30	HE010830	HE010830BK	HE010830NY	100
	35	HE010835	HE010835BK	HE010835NY	100
	40	HE010840	HE010840BK	HE010840NY	100
	45	HE010845	HE010845BK	HE010845NY	100
	50	HE010850	HE010850BK	HE010850NY	100
M10	55	HE010855	HE010855BK	HE010855NY	100
	60	HE010860	HE010860BK	HE010860NY	100
	20	HE011020	HE011020BK	HE011020NY	100
	25	HE011025	HE011025BK	HE011025NY	100
	30	HE011030	HE011030BK	HE011030NY	100
	35	HE011035	HE011035BK	HE011035NY	100
	40	HE011040	HE011040BK	HE011040NY	50
	50	HE011050	HE011050BK	HE011050NY	50
	60	HE011060	HE011060BK	HE011060NY	50
	70	HE011070	HE011070BK	HE011070NY	50
M12	20	HE011220	HE011220BK	HE011220NY	10
	25	HE011225	HE011225BK	HE011225NY	10
	30	HE011230	HE011230BK	HE011230NY	10
	35	HE011235	HE011235BK	HE011235NY	10
	40	HE011240	HE011240BK	HE011240NY	10
	50	HE011250	HE011250BK	HE011250NY	10
	60	HE011260	HE011260BK	HE011260NY	10
	70	HE011270	HE011270BK	HE011270NY	10
	80	HE011280	HE011280BK	HE011280NY	10
	90	HE011290	HE011290BK	HE011290NY	10
100	HE0112100	HE0112100BK	HE0112100NY	10	

1 本から出荷致します！詳しくはお問い合わせください。
製品コード末尾「B K」＝黒染め、「N Y」＝ナイロック加工。

※印のサイズは半ネジとなります。

- ・ M8x5/M8x6 ネジ部長さ=50mm
- ・ M10x50/M10x60/M10x70 ネジ部長さ=40mm
- ・ M12x70/M12x80/M12x90/M12x100 ネジ部長さ=60mm