


LQ3 Series

外形寸法図

フィメールブランチティ：LQ3B-F

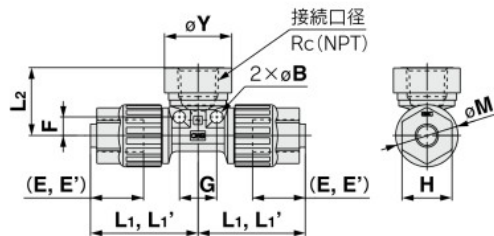

(E, E') はナット端面からの必要チューブ挿入
代参考寸法です。
(E'), L1' はナット材質:PVDFの寸法です。

ミリサイズ

型式	適用 チューブ 外径	接続ねじ Rc・NPT	B	E	E'	F	G	H	L ₁	L ₁ '	L ₂	M	最小 穴径	Y
LQ3B11-F□	φ4	1/8"	3.5	10	9	4.8	9.5	11	28.5	27.5	19.5	14	2.5	18.5
LQ3B12-F□	φ3	1/8"											2	
LQ3B21-F□	φ6	1/8"	4	17	16	6	12	16	34.5	33.5	20	20	4	18.5
LQ3B22-F□		1/4"									22			21.5
LQ3B31-F□	φ10	1/8"									23		7.5	18.5
LQ3B32-F□	φ8	1/8"											6.4	
LQ3B33-F□	φ10	1/4"	5	22.5	19.5	9	18	21	47.5	44.5	24	25	7.5	21.5
LQ3B34-F□	φ8	1/4"											6.4	
LQ3B35-F□	φ10	3/8"									25.5		7.5	25
LQ3B36-F□	φ8	3/8"											6.4	
LQ3B41-F□	φ12	1/4"	6	24	22	10	20	24	52.5	50.5	23.5	29	9.5	21.5
LQ3B42-F□		3/8"									26			25
LQ3B43-F□		1/2"									30			29.5
LQ3B51-F□	φ19	3/8"	7	26.5	24	14	28	32	64	61.5	30.5	37	14	25
LQ3B52-F□		1/2"									35.5		16	29.5
LQ3B53-F□		3/4"									37			36
LQ3B61-F□	φ25	1/2"	8	30	26	18	36	41	78	74	41	49	17.5	29.5
LQ3B62-F□		3/4"									42.5		22	36
LQ3B63-F□		1"									46			44.5

インチサイズ

型式	適用 チューブ 外径	接続ねじ Rc・NPT	B	E	E'	F	G	H	L ₁	L ₁ '	L ₂	M	最小 穴径	Y
LQ3B1A-F□	1/8"	1/8"	3.5	10	9	4.8	9.5	11	28.5	27.5	19.5	14	2	18.5
LQ3B2A-F□	1/4"	1/8"	4	17	16	6	12	16	34.5	33.5	20	20	4	18.5
LQ3B2B-F□		1/4"									22			21.5
LQ3B3A-F□	3/8"	1/8"	5	22.5	19.5	9	18	21	47.5	44.5	23	25	6.4	18.5
LQ3B3B-F□		1/4"									24			21.5
LQ3B3C-F□		3/8"									25.5			25
LQ3B4A-F□	1/2"	1/4"	6	24.5	22.5	10	20	24	52.5	50.5	23.5	29	9.5	21.5
LQ3B4B-F□		3/8"									26			25
LQ3B4C-F□		1/2"									30			29.5
LQ3B5A-F□	3/4"	3/8"	7	26.5	24	14	28	32	64	61.5	30.5	37	14	25
LQ3B5B-F□		1/2"									35.5		16	29.5
LQ3B5C-F□		3/4"									37			36
LQ3B6A-F□	1"	1/2"	8	30	26	18	36	41	78	74	41	49	17.5	29.5
LQ3B6B-F□		3/4"									42.5		22	36
LQ3B6C-F□		1"									46			44.5