

外形寸法図

メスユニオン:KFF

(mm)




〈樹脂スリーブ〉




〈黄銅スリーブ〉

適用チューブ サイズ mm		接続 ねじ Rc	型式	六角対辺		L ₁	L ₂	L ₃	M	ød	有効 断面積 mm ²	質量g	
外径	内径			H ₁	H ₂								
ø4	ø2.5	Rc1/4	KFF04-02	17	10	33.5	26.8	15	15.5	1.5	1.6	25	
			KFF04B-02			30.4	27.4		12.4			26	
ø6	ø4	Rc1/4	KFF06-02	17	12	33.2	26.5	15	15.2	3	6	27	
		Rc3/8	KFF06-03	19		35.2	28.5	17	30				
		Rc1/4	KFF06B-02	17		30.2	27.2	15	28				
		Rc3/8	KFF06B-03	19		32.2	29.2	17	31				
ø8	ø5	Rc1/4	KFF08U-02	17	14	33.2	26.5	15	16.2	4	11	28	
	ø6		KFF08N-02			30.3	27.3		13.3	5	17	29	
			KFF08B-02										
ø10	ø6.5	Rc1/4	KFF10U-02	17	17	34.8	27.5	15	18.8	5.5	21	32	
	ø7.5		KFF10N-02			31.0	28.0		15.0	6.5	30	33	
			KFF10B-02										
ø12	ø8	Rc1/4	KFF12U-02	17	19	35.3	28.5	15	19.3	7	35	35	
	ø9		KFF12N-02			31.6	28.6		15.5	8	45	36	
			KFF12B-02										

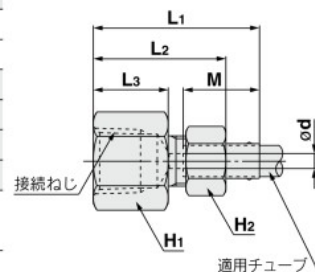


隔壁用メスユニオン:KFE

(mm)

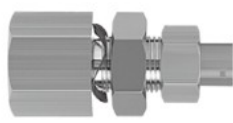


〈樹脂スリーブ〉

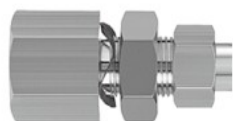

〈黄銅スリーブ〉

適用チューブ サイズ mm		接続 ねじ Rc	型式	六角対辺			L ₁	L ₂	L ₃	M	ød	T ₂	取付穴	有効 断面積 mm ²	質量 g
外径	内径			H ₁	H ₂	H ₃									
ø6	ø4	Rc1/4	KFE06-02	17	12	17	44.2	37.5	16	15.2	3	M10×1	11	6	41
			KFE06B-02				41.2	38.2		12.2				42	
ø8	ø5	Rc3/8	KFE08U-03	19	14	19	46.2	39.5	17	16.2	4	M12×1	13	11	49
	ø6		KFE08N-03							5	17			50	
			KFE08B-03				43.3	40.3		13.3	51				
ø10	ø6.5	Rc3/8	KFE10U-03	19	17	22	48.8	41.5	17	18.8	5.5	M15×1	16	21	63
	ø7.5		KFE10N-03							6.5	30			62	
			KFE10B-03				45.0	42.0		15.0	63				
ø12	ø8	Rc3/8	KFE12U-03	22	19	24	51.3	44.5	17	19.3	7	M17×1	18	35	93
	ø9		KFE12N-03							8	45			91	
			KFE12B-03				47.6	44.6		15.5	93				

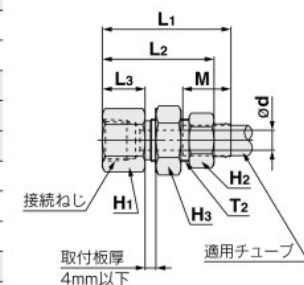

隔壁用ユニオン:KFE

(mm)



〈樹脂スリーブ〉



〈黄銅スリーブ〉

適用チューブ サイズ mm		型式	六角対辺			L ₁	L ₂	M	ød	取付穴	有効 断面積 mm ²	質量g
			H ₁	H ₂	H ₃							
ø4	ø2.5	KFE04-00	12	10	13	50.9	37.6	15.5	1.5	9	1.6	23
		KFE04B-00				44.7	38.8	12.4				24
ø6	ø4	KFE06-00	14	12	17	51.3	38	15.2	3	11	6	34
		KFE06B-00				45.3	39.4	12.2				36
ø8	ø5	KFE08U-00	17	14	19	52.3	39	16.2	4	13	11	47
	ø6	KFE08N-00				46.5	40.6	13	5		17	46
		KFE08B-00										48
ø10	ø6.5	KFE10U-00	19	17	22	56.6	42	18.8	5.5	16	21	67
	ø7.5	KFE10N-00				49.0	43.0	15.0	6.5		30	66
		KFE10B-00										69
ø12	ø8	KFE12U-00	22	19	24	59.5	46	19.3	7	18	35	87
	ø9	KFE12N-00				52.1	46.2	15.5	8		45	85
		KFE12B-00										88

