


# 快速排氣調速閥

# ASV Series

RoHS

本體尺寸：M3, M5, 1/8, 1/4, 3/8

## 型號表示方法

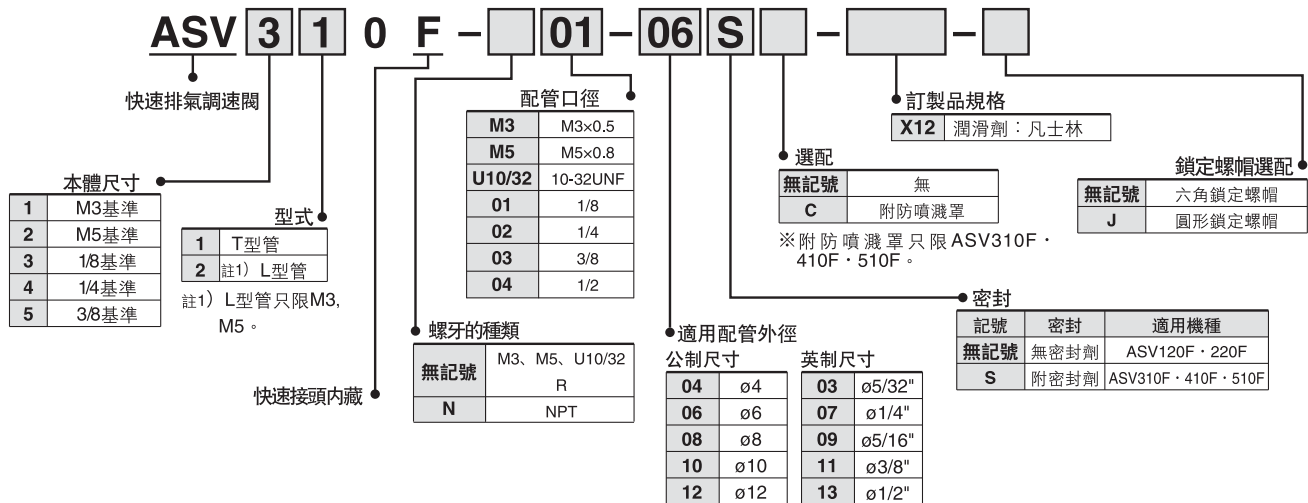


快速排氣閥＋排氣節流閥一體型。  
可對應氣缸的高速驅動

- 約可得2倍的有效斷面積。  
(與調速閥控制時的比較)  
對應機種：ASV310F、410F、510F
- 消音器・快速接頭內藏
- 難燃性樹脂本體(UL規格V-0)  
對應機種：ASV310F、410F、510F
- 黃銅零件全部無電鍍鍍處理



表示記號

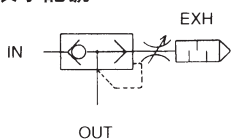

訂製品

Order Made

潤滑劑：凡士林

X12

(例) ASV120F-M3-04-X12

註1) 只對應ASV120F, ASV220F。

## 型式

型式	配管口徑	配管外徑 (mm)										有效斷面積 (mm <sup>2</sup> )		
		4	6	8	10	12	5/32"	1/4"	5/16"	3/8"	1/2"	IN→OUT	OUT→EXH.	
ASV120F-M3	M3×0.5	●											0.3	0.3
ASV220F-M5	M5×0.8	●	●										1.3	1.3
ASV310F-01	R1/8		●	●									7	8
ASV310F-02	R1/4		●	●									7	8
ASV410F-01	R1/8			●	●								13.5	14
ASV410F-02	R1/4			●	●								13.5	14
ASV410F-03	R3/8			●	●								13.5	14
ASV510F-02	R1/4				●	●							23	27
ASV510F-03	R3/8				●	●							27	29
ASV510F-04	R1/2					●	●						27	29
ASV220F-U10/32	10-32UNF						●	●					1.3	1.3
ASV310F-N01	NPT1/8							●	●				7	8
ASV310F-N02	NPT1/4							●	●				7	8
ASV410F-N01	NPT1/8								●	●			13.5	14
ASV410F-N02	NPT1/4								●	●			13.5	14
ASV410F-N03	NPT3/8								●	●			13.5	14
ASV510F-N02	NPT1/4									●	●		23	27
ASV510F-N03	NPT3/8									●	●		27	29
ASV510F-N04	NPT1/2										●	●	27	29

## 規格

系列	ASV120F	ASV220F	ASV310F・410F	ASV510F
使用流體	空氣			
保證耐壓力	1.5MPa			
最高使用壓力	1MPa			
最低使用壓力	0.1MPa			
周圍溫度及使用流體溫度	-5~60°C (不結冰)			
針閥回轉數	10回轉	8回轉	12回轉	15回轉
註1) 適用配管材質	尼龍、軟尼龍、聚氨酯			
選配	圓形鎖定螺帽		附防噴濺罩、圓形鎖定螺帽	

註1) 軟尼龍、聚氨酯請注意最高使用壓力。