


LQ1 系列

外形尺寸圖

陽牙L形彎頭：LQ1L-M

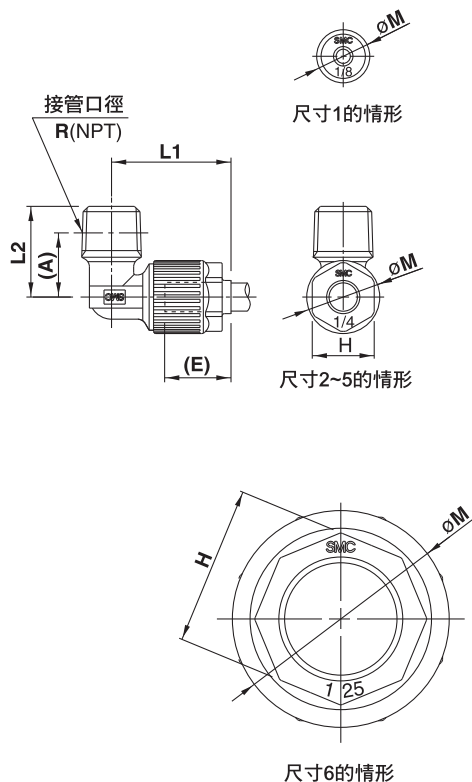

(A) 為旋入後的參考尺寸。
(E) 為從螺帽端面的必要管插入代表編號參考尺寸。

毫米尺寸

型式	適用管 外徑	連接螺牙 R·NPT	A	E	H	L1	L2	M
LQ1L11-M□	ø4	1/8"	11.5	10	—	18	15	ø11.5
LQ1L12-M□	ø3							
LQ1L21-M□	ø6	1/8"	14.5	15	14	27	20.5	ø16.5
LQ1L22-M□	ø4							
LQ1L23-M□	ø6	1/4"	20	20	17	35	26.5	ø23
LQ1L24-M□	ø4							
LQ1L31-M□	ø10	1/4"	25	24	21	45	33	ø28
LQ1L32-M□	ø8							
LQ1L33-M□	ø6	3/8"	30.5	29	26	54	40	ø39
LQ1L34-M□	ø10							
LQ1L35-M□	ø8	3/4"	35	39.5	36	68.5	46	ø49
LQ1L36-M□	ø6							
LQ1L41-M□	ø12	3/8"	25	24	21	45	33	ø28
LQ1L42-M□	ø10							
LQ1L43-M□	ø12	1/2"	30.5	29	26	54	40	ø39
LQ1L44-M□	ø10							
LQ1L51-M□	ø19	1/2"	35	39.5	36	68.5	46	ø49
LQ1L52-M□	ø12							
LQ1L53-M□	ø19	3/4"	35	39.5	36	68.5	46	ø49
LQ1L54-M□	ø12							
LQ1L61-M□	ø25	3/4"	35	39.5	36	68.5	46	ø49
LQ1L62-M□	ø19							
LQ1L63-M□	ø25	1"	35	39.5	36	68.5	46	ø49
LQ1L64-M□	ø19							

英吋尺寸

型式	適用管 外徑	連接螺牙 R·NPT	A	E	H	L1	L2	M
LQ1L1A-M□	1/8"	1/8"	11.5	10	—	18	15	ø11.5
LQ1L2A-M□	1/4"							
LQ1L2B-M□	3/16"	1/8"	14.5	15	14	27	20.5	ø16.5
LQ1L2C-M□	1/8"							
LQ1L2D-M□	1/4"	1/4"	20	20	17	35	26.5	ø23
LQ1L2E-M□	3/16"							
LQ1L2F-M□	1/8"	3/8"	25	24	21	45	33	ø28
LQ1L3A-M□	3/8"							
LQ1L3B-M□	1/4"	3/8"	30.5	29	26	54	40	ø39
LQ1L3C-M□	3/8"							
LQ1L3D-M□	1/4"	1/2"	35	39.5	36	68.5	46	ø49
LQ1L4A-M□	1/2"							
LQ1L4B-M□	3/8"	3/8"	35	39.5	36	68.5	46	ø49
LQ1L4C-M□	1/2"							
LQ1L4D-M□	3/8"	1/2"	35	39.5	36	68.5	46	ø49
LQ1L5A-M□	3/4"							
LQ1L5B-M□	1/2"	3/4"	35	39.5	36	68.5	46	ø49
LQ1L5C-M□	3/4"							
LQ1L5D-M□	1/2"	1"	35	39.5	36	68.5	46	ø49
LQ1L6A-M□	1"							
LQ1L6B-M□	3/4"	1"	35	39.5	36	68.5	46	ø49
LQ1L6C-M□	1"							
LQ1L6D-M□	3/4"	1"	35	39.5	36	68.5	46	ø49
LQ1L6E-M□	1"							