


陰牙分流接頭：LQ1B-F

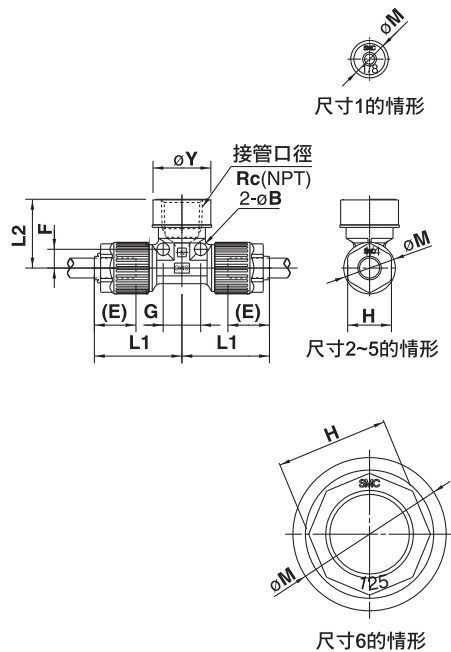

毫米尺寸

型式	適用管 外徑	連接螺牙 Rc·NPT	B	E	F	G	H	L1	L2	M	Y
LQ1B11-F□	ø4	1/8"	ø2	10	4	8	-	18.5	16	ø11.5	ø18.5
LQ1B12-F□	ø3										
LQ1B21-F□	ø6	1/8"	ø4	15	6	12	14	28	19.5	ø16.5	ø18.5
LQ1B22-F□	ø4										
LQ1B23-F□	ø6	1/4"	ø4	15	6	12	14	28	22	ø16.5	ø21.5
LQ1B24-F□	ø4										
LQ1B31-F□	ø10	1/4"	ø5	20	9	18	17	36.5	23.7	ø23	ø21.5
LQ1B32-F□	ø8										
LQ1B33-F□	ø6	3/8"	ø5	20	9	18	17	36.5	25.5	ø23	ø25
LQ1B34-F□	ø10										
LQ1B35-F□	ø8	3/8"	ø5	20	9	18	17	36.5	25.5	ø23	ø25
LQ1B36-F□	ø6										
LQ1B41-F□	ø12	3/8"	ø6	24	9	18	21	43	25	ø28	ø25
LQ1B42-F□	ø10										
LQ1B43-F□	ø12	1/2"	ø6	24	9	18	21	43	31.5	ø28	ø29.5
LQ1B44-F□	ø10										
LQ1B51-F□	ø19	1/2"	ø7	29	14	28	26	54	35.5	ø39	ø29.5
LQ1B52-F□	ø12										
LQ1B53-F□	ø19	3/4"	ø7	29	14	28	26	54	37	ø39	ø36
LQ1B54-F□	ø12										
LQ1B61-F□	ø25	3/4"	ø8	39.5	18	36	36	69.5	42.5	ø49	ø36
LQ1B62-F□	ø19										
LQ1B63-F□	ø25	1"	ø8	39.5	18	36	36	69.5	46	ø49	ø44.5
LQ1B64-F□	ø19										

(E) 為從螺帽端面的必要管插入代表編號參考尺寸。

英吋尺寸

型式	適用管 外徑	連接螺牙 Rc·NPT	B	E	F	G	H	L1	L2	M	Y
LQ1B1A-F□	1/8"	1/8"	ø2	10	4	8	-	18.5	16	ø11.5	ø18.5
LQ1B2A-F□	1/4"										
LQ1B2B-F□	3/16"	1/8"	ø4	15	6	12	14	28	19.5	ø16.5	ø18.5
LQ1B2C-F□	1/8"										
LQ1B2D-F□	1/4"	1/4"	ø4	15	6	12	14	28	22	ø16.5	ø21.5
LQ1B2E-F□	3/16"										
LQ1B2F-F□	1/8"	1/4"	ø5	20	9	18	17	36.5	23.7	ø23	ø21.5
LQ1B3A-F□	3/8"										
LQ1B3B-F□	1/4"	3/8"	ø5	20	9	18	17	36.5	25.5	ø23	ø25
LQ1B3C-F□	3/8"										
LQ1B3D-F□	1/4"	3/8"	ø6	24	9	18	21	43	25	ø28	ø25
LQ1B4A-F□	1/2"										
LQ1B4B-F□	3/8"	1/2"	ø6	24	9	18	21	43	31.5	ø28	ø29.5
LQ1B4C-F□	1/2"										
LQ1B4D-F□	3/8"	1/2"	ø7	29	14	28	26	54	35.5	ø39	ø29.5
LQ1B5A-F□	3/4"										
LQ1B5B-F□	1/2"	3/4"	ø7	29	14	28	26	54	37	ø39	ø36
LQ1B5C-F□	3/4"										
LQ1B5D-F□	1/2"	1"	ø8	39.5	18	36	36	69.5	42.5	ø49	ø36
LQ1B6A-F□	1"										
LQ1B6B-F□	3/4"	1"	ø8	39.5	18	36	36	69.5	46	ø49	ø44.5
LQ1B6C-F□	1"										
LQ1B6D-F□	3/4"	1"	ø8	39.5	18	36	36	69.5	46	ø49	ø44.5
LQ1B6E-F□	1/2"										