

## TORQUE HINGE HG-TA



- Highly durable HG-TA45H with wire hole is newly launched 1.

## [Specifications]

- Operating temperature: 0°C~40°C

## [Applications]

- LCD, monitoring camera, etc.

## [Remarks]

- Be sure to read the "Cautions" 2.
- For pair using: Please use the same torque in both hinges.
- When installing, ensure that both hinge shafts are levelled and aligned.

## Selection Tool




## Video Link





Sasuga-kun




## [Application Example]

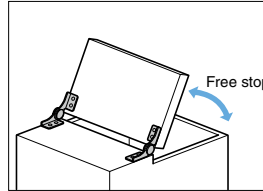


Marking:  
HG-TA20...[20]  
HG-TA30...[30]

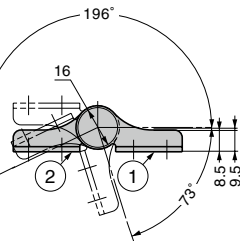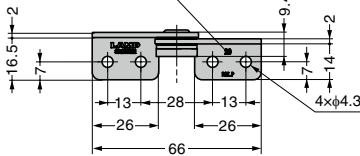

HG-TA20L, HG-TA30L

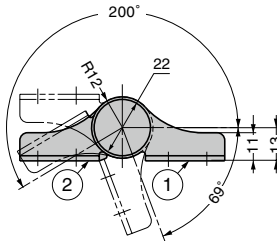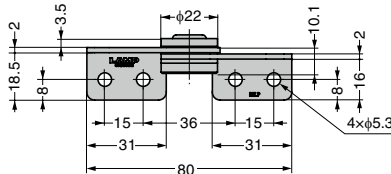 

HG-TA45L

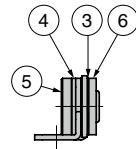

No.	Part Name	Material	Finish
①	Bracket	Stainless Steel (SUS430)	Barrel Polished
②	Base		
③	F Plate	Bronze	-
④	Spring Washer	Steel	
⑤	Shaft	Stainless Steel (SUS303)	
⑥	Washer	Stainless Steel (SUS430)	Barrel Polished

RHS	CAD	Item Code	Item Name	Description	Type	Torque N·m/pc	Torque kgf·cm/pc	Weight (g)	Box (pcs)	Carton (pcs)
G	3D	170-012-403	HG-TA20R	Without wire hole	Right-handed	2.0±20%	20.4±20%	30	40	320
G	3D	170-012-404	HG-TA20L		Left-handed					
G	3D	170-012-405	HG-TA30R		Right-handed	3.0±20%	30.6±20%		40	320
G	3D	170-012-406	HG-TA30L		Left-handed					
G	3D	170-012-407	HG-TA45R	Right-handed	4.5±20%	45.9±20%	65	20	160	
G	3D	170-012-408	HG-TA45L	Left-handed						

Refer to 1 : P.76, 2 : P.43